

All HE13/HE14 IDC Receptacle, SRRA, AWG26 (3)

Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

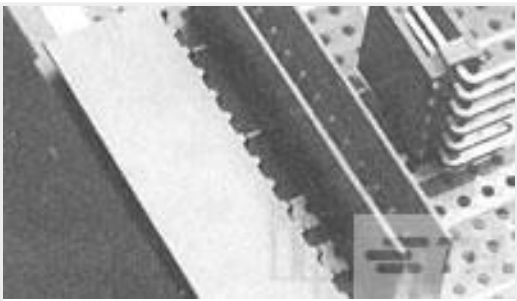

TE Part # 281698-5
HEADER HE14 RA 5 P

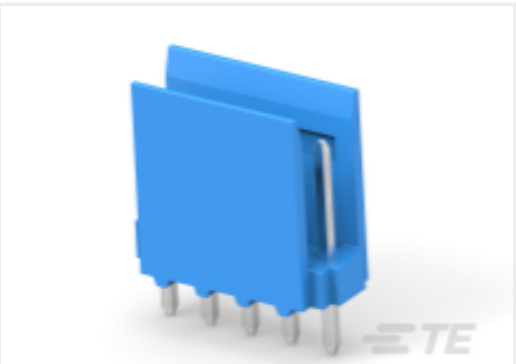

TE Part # 281695-5
HEADER HE14 STRAIGHT 5 P

Customers Also Bought



TE Part #1623925-8
CFR100 5% 150R



TE Part #1-1614937-5
CPF0805 4K7 0.1% 25PPM 5K RL




TE Part #1624351-1
NTC0805 5% 20K



TE Part #1622565-1
LR1 1% 75K



TE Part #2-1623932-4
CFR50 5% 150R

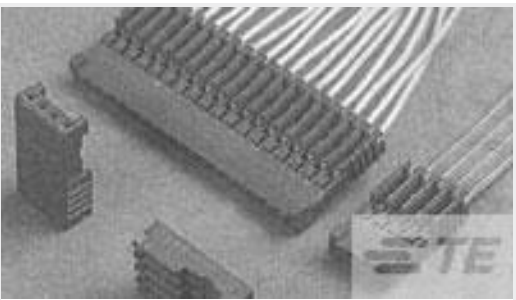

TE Part #281783-4
PLUG HE14 IDC 180 4 P AWG 26-24




TE Part #5052842031
RNF-100-3/64-0-STK



TE Part #1623773-6
C10 4R7 5% (LOOSE)



TE Part #1-1623933-2
CFR50 5% 390R

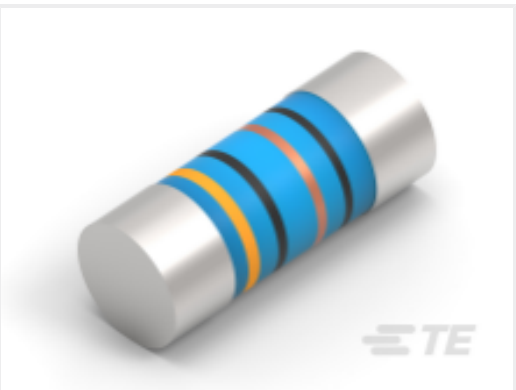

TE Part #9-2176316-0
MELF SMA-A 150K 1% 50PPM 0207 1W

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_144271-5_D.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_144271-5_D.3d_igs.zip

English



Customer View Model
[ENG_CVM_CVM_144271-5_D.3d_stp.zip](#)
English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

[Product Specifications](#)
[Application Specification](#)
English