


RS PRO 1.5 mm² Flexible Cable, 50 m Length

RS Stock No: 606-067

FEATURES

- **Annealed Copper Conductor:** Provides superior conductivity and flexibility
- **PVC Jacket:** Offers protection against abrasion and environmental factors
- **4 Cores:** Suitable for complex wiring requirements
- **Temperature Range -15 °C to 70 °C:** Operates effectively in various environments
- **Voltage Rating 500 V:** Suitable for medium voltage applications
- **Plain Conductor Type:** Ensures ease of installation and handling
- **30/0.25 Core Strands:** Enhances flexibility and durability
- **Black Jacket Colour:** Ideal for discreet installations

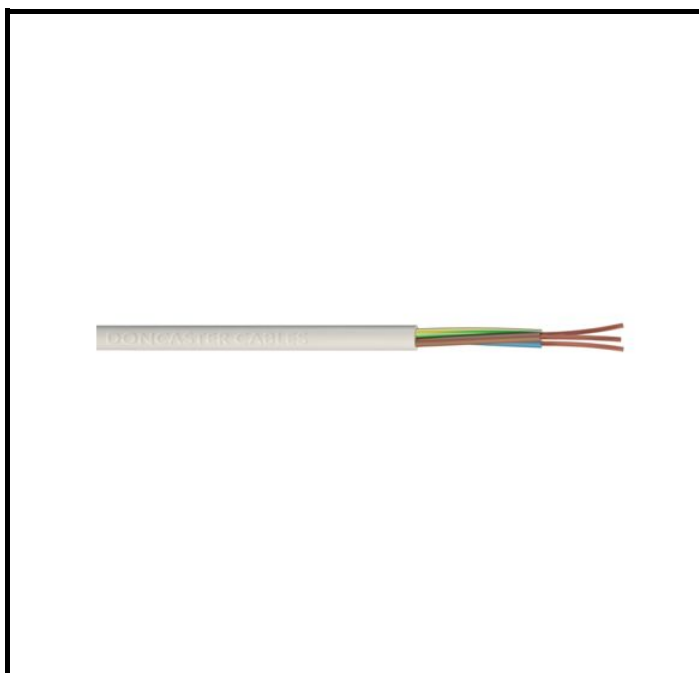

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO flexible cable is designed for a wide range of electrical applications, offering reliable performance and durability. With a conductor made from annealed copper, it ensures excellent conductivity and flexibility, making it ideal for installations where space is limited. The cable's robust PVC jacket provides protection against environmental factors, ensuring longevity and safety.

General Specifications

Conductor Material	Annealed Copper
Conductor Type	Plain
Jacket Colour	Black
Product Type	Flexible Cable

Mechanical Specifications

Cable CSA	1.5 mm ²
Cable Length	50 m
Core Strands	30/0.25
Jacket Material	Polyvinyl Chloride
Number of Cores	4
Outside Diameter	10.5 mm

Operation Environment Specifications

Maximum Operating Temperature	70 °C
Minimum Operating Temperature	-15 °C

Approvals

Standards/Approvals	ACI, BASEC ISO 9001 UKAS CS1-029, BS EN 50363-3, BS EN 50363-4-1, BS EN 50525-2-11, BS EN 60228
---------------------	---

Electrical Specifications

Voltage	500 V
---------	-------