

規格

MICROPHONE SPECIFICATIONS

項目:

1. ITEM: DYNAMIC GOOSENECK MICROPHONE

型號:

2. PART NO.: 3022283

電氣規格:

3. ELECTRICAL SPECIFICATIONS:

- 3.1 Directional Characteristics : Unidirectional (Cardioid)
- 3.2 Frequency : 100 Hz ~ 16,000 Hz
- 3.3 Impedance : $500\Omega \pm 30\%$ (at 1,000 Hz)
- 3.4 Sensitivity : $-75\text{ dB} \pm 3\text{ dB}$ (0 dB = 1 V/microbar, 1,000 Hz indicated by open circuit)
- 3.5 Switch : Push Button

機械規格:

4. MECHANICAL SPECIFICATIONS:

- 4.1 Dimensions : $\phi 29\text{mm}$ (mic head) x 390mm (total length)
- 4.2 Connector : 3 Pin XLR (male)

測試規模:

5. METHOD OF MEASUREMENT:

According to JIS C-5502


測試儀器:

6. TEST INSTRUMENT :

Brüel & Kjær – Type 2012 with digital turntable system

曲線圖:

7. FREQUENCY RESPONSE CURVE:

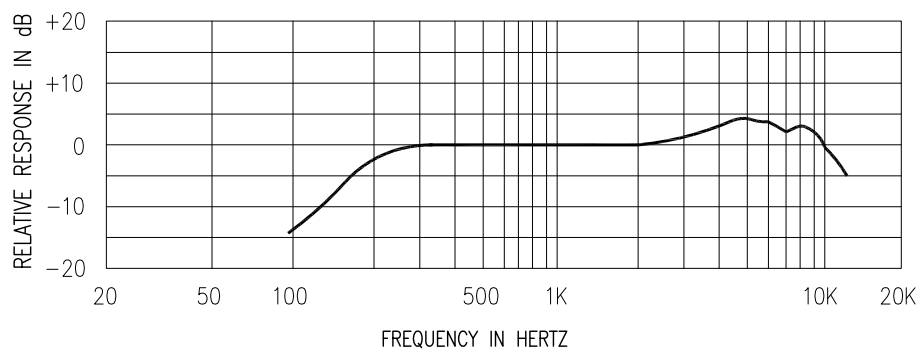

ELECTRET SPEC. CHECKED BY :

MECHANICAL SPEC. CHECKED BY :

PREPARED BY :