


Mounting plate 3VA20 (100 A), 3VA21 (160 A), 3VA22 (250 A), 3 or 4-pole, fixed-mounted, plug-in design, withdrawable, RCD: without, H: 200 mm W: 600 mm

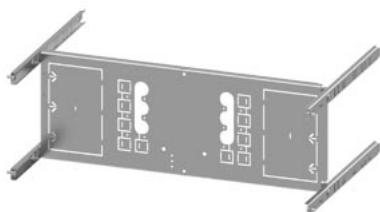

Model	
product brand name	SIVACON S4
General technical data	
surface processing	Galvanized
product feature perforated	Yes
Mechanical Design	
height	200 mm
width	600 mm
depth	400 mm
net weight	2.48 kg
material	sheet-steel
Approvals Certificates	
General Product Approval	other



[Miscellaneous](#)



[Miscellaneous](#)

other	Environment
Confirmation	Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875 Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ6000-8BA08 Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/8PQ6000-8BA08 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ6000-8BA08 CAX-Online-Generator http://www.siemens.com/cax Tender specifications http://www.siemens.com/specifications

