




Datasheet

Stock No: 340-6158

RS Pro Perforated Steel Sheet

ENGLISH

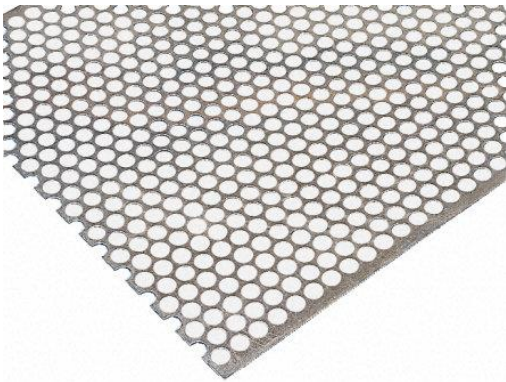

Product Details

Stainless Steel 316

- Type 316 austenitic (non magnetic)
- High corrosion resistance
- Chemical, food, photography and marine uses
- Selvedged border
- Tolerance on length $\pm 1\%$
- Sheet size 500 x 500 mm
- Thickness 0.55mm (24 swg)

Specifications:

Material:	Stainless Steel
Length:	500mm
Width:	500mm
Thickness:	0.55mm
Hole Size:	4.7 mm ²
Open Area Percentage:	35%
Hole Layout:	in Line
Pattern Number:	11



Metal & Plastic

Dimensions (mm)					
Pattern	Hole(mm)	Open Area	Pitch I (mm)	Pitch II (mm)	Hole Configuration
1	1.2 \emptyset	42%	1.7	3.2	60°
2	1.5 \emptyset	22%	4	4	45°
3	1.7 \emptyset	45%	2.4	4.1	60°
4	2.0 \emptyset	47%	2.8	4.8	60°
5	3.0 \emptyset	33%	5	8.7	60°
6a	3.0 \emptyset	51%	4	6.9	60°
6	4.8 \emptyset	50%	6.5	11.2	60°
7	6.4 \emptyset	43%	9.2	16	60°
8	8.0 \emptyset	68%	9.2	16	60°
9	6.0 x 6.0	62%	7.6	7.6	Square
10	6.0 x 6.0	52%	9.1	7.6	Staggered
11	4.7 x 4.7	35%	8	8	Square
12	2.4 x 12.7	34%	4.8	15.1	Rect
13	6.0 A/F	79%	6.76	11.63	Hex
14	10.0 x 10.0	59%	13	13	Square
15	1.0 \emptyset	46%	1.4	2.4	60°