

## Features

- LED Unit
- Self-configuration
- 60mm
- 24V DC

## RS PRO Signal Tower, 24V DC, LED Unit, 60mm

RS Stock No.:245-785, 245-787, 245-788,  
145-726, 145-725



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

Enhance your RS PRO 24V signal tower performance with our newly re-designed RS PRO LED light modules. These beacons provide brilliant, even LED light, ensuring visibility at greater distances. The innovative "Twist and Lock" system allows for effortless customisation, making it easier to adapt your RS PRO 24 V signal tower to your specific needs.

## General Specifications

Lens	PC
Nominal flash rate	-
Bulb Type	LED
Light Effect	Continuous Lighting
Lens Colour	Red/Amber/Green/Blue/Yellow
Fitting	-
Magnetic type	No
Flash Pattern	-
Housing Colour	-
Lamp Include	Yes
Multifunction	No
Number of flash patterns	-
Number of LED	1
Special Features	Easily customize and field configure LED units and sound modules

## Electrical Specifications

Supply Voltage	24V DC
Light Output	LED
Current Type	DC
Current Consumption	Max. 45mA

## Mechanical Specifications

Dimensions	60 (w) x 60 (d) x 50mm (h)
Base Diameter	-
Base Length	-
Base Width	-
Mounting Style	-
Weight	0.06kg

## Operation Environment Specifications

Maximum Temperature	-20°C
Minimum Temperature	+50°C

## Protection Category

IP Rating	-
-----------	---

## Classification


eCl@ss Version	-
UNSPSC Version	-

## Approvals

Compliance/Certifications	CE/UKCA
Declarations	-
Standards Met	RoHS Compliant
Hazardous Area Certification	-

## ■ Outer Dimensions

(Unit:mm)

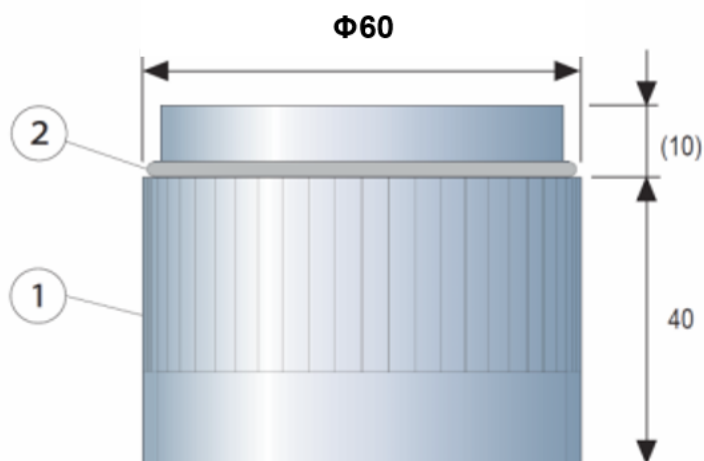

No.	Name	Material	UL Flammability
1	Globe	PC	V-2
2	O-ring	Silicone Rubber	-