

Isolierkörpermaterial

PBT, UL94V-0

Kontaktmaterial

Messing

Kontaktoberfläche

Ni, Sn

Kontaktwiderstand

20mΩ max

Isolationswiderstand

1000MΩ min

Strombelastbarkeit

3A

Betriebstemperatur

-40°C - +105°C

Betriebsspannung

250V AC

Prüfspannung

500V AC

Verpackung

Blisterverpackung

Insulator material

PBT, UL94V-0

Contact material

Brass

Plating

Ni, Sn

Contact resistance

20mΩ max

Insulation resistance

1000MΩ min

Current rating

3A

Operating temperature

-40°C to +105°C

Operating voltage

250V AC


Test voltage

500V AC

Packing

Tray packing

Dimensions			
No. of contacts	A	B	C
10	17,48	10,16	18,17
14	22,56	15,24	23,25
16	25,10	17,78	25,79
20	30,18	22,87	30,87
26	37,80	30,48	38,49
34	47,96	40,64	48,65
40	55,58	48,26	56,27
50	68,28	60,96	68,97
60	80,98	73,66	81,67
64	86,06	78,74	86,75

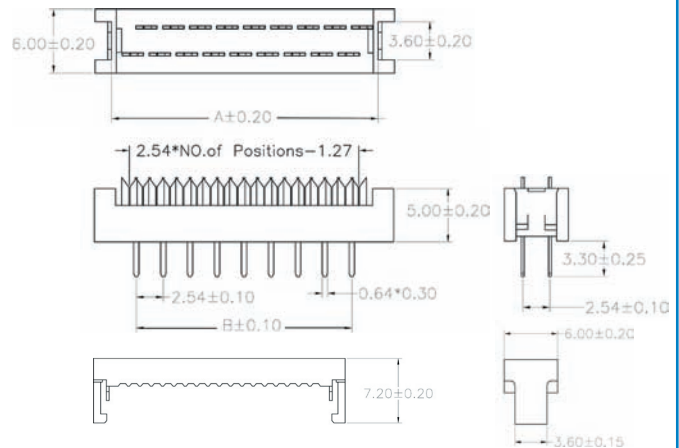

Bestellcode / Ordercode

Polzahl

10 / 14 / 16 / 20 /
26 / 34 / 40 / 50 / 60 / 64

No. of contacts

10 / 14 / 16 / 20 /
26 / 34 / 40 / 50 / 60 / 64

AWLP **xx** / **3,2** **T**

Bitte „x“ durch die geeignete Option ersetzen
Please replace „x“ with appropriate option