

## Features

- Strong and durable stainless-steel 304 construction
- 120-degree opening angle
- Removable pin which allows quick and easy removal of the door giving improved access for maintenance
- Easy mounting via either metric bolts or rivets

## RS PRO Hinges

RS Stock No.: 0335184



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description


*Stainless steel hinge, pin and circlip. 120 degree opening angle. A removeable pin allows the door to be separated from the enclosure, giving improved access. The pin is secured with a circlip. Designed for use in industrial enclosures and cabinets.*

## General Specifications

<b>Length</b>	80mm
<b>Material</b>	Stainless steel 304
<b>Opening angle</b>	120 degrees
<b>Colour</b>	Grey
<b>Application</b>	Enclosures, HVAC, machinery, equipment, construction industry
<b>Radial load (N)</b>	310
<b>Axial load (N)</b>	480

## Mechanical Specifications

A	80
B	66
C	42
D	-
E	36.5
F	6.5
G	9.5
H	6.5
I	12
J	20
K	54.3

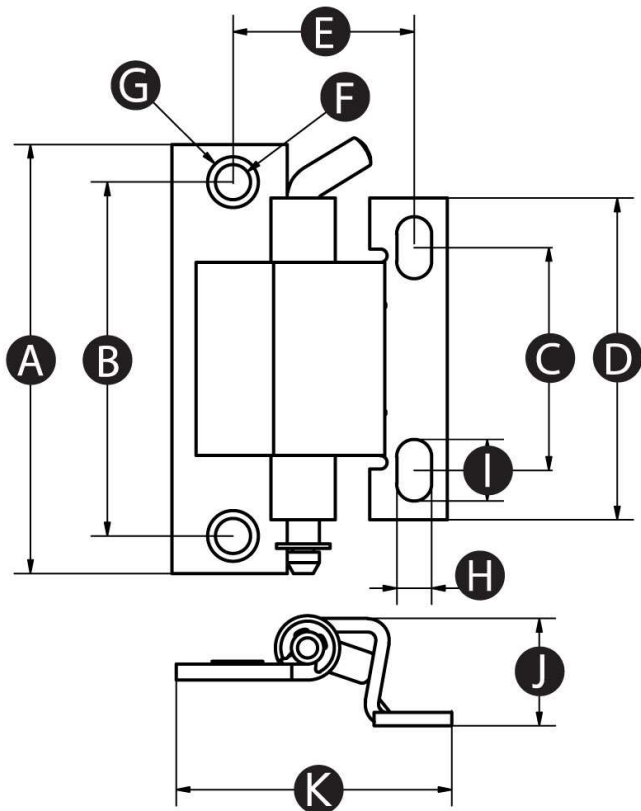

## Similar Products

Stock No.	Brand	Product Name	Length	Opening Angle
0335183	RS PRO	Zinc Plated Steel Concealed Hinge	80mm	120 degrees
0335184	RS PRO	Stainless Steel Concealed Hinge	80mm	120 degrees
0335186	RS PRO	Zinc Plated Steel Concealed Hinge	80mm	120 degrees
0335153	RS PRO	Stainless Steel Concealed Hinge	80mm	120 degrees
0335180	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	120 degrees
0335181	RS PRO	Stainless Steel Concealed Hinge	60mm	120 degrees
0335175	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	120 degrees
0335177	RS PRO	Stainless Steel Concealed Hinge	60mm	120 degrees
0335178	RS PRO	Zinc Plated Steel Concealed Hinge	60mm	100 degrees