

Overvoltage protection aluminum socket strip 5-fold with switch

Item-No.: 0606x00052031 (1,5 m cord)



Noble, transparent anodized aluminum case, matt

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm


1,5 m power cord and angle plug (optional with 3 m or 5m power cord)

Increased safety due to integrated child protection

End caps with mounting facility


Optical function display

The connected devices will remain in operation after release overvoltage protection

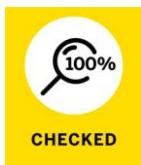

Overvoltage protection aluminum socket strip 5-fold with switch

Technical data

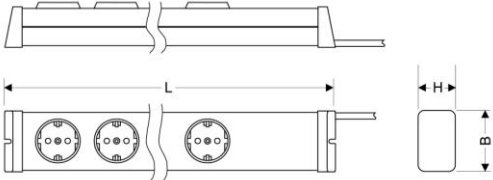3.600 W Power	250 V ~ / 50 Hz Rated voltage	16 A Rated current
<p>Power Cord: H05VV-F 3G 1,5 mm² Plug: CEE 7/7 plug Type EF, angled Sockets: earthing contact Type F Switch: 2-pole, illuminated Consumption per switch: < 0,4 W Voltage U_n: 230 V~ Max. continuous operation voltage U_c: 255 V~ U_{oc}: 5000 V Protection level Up: L-N < 1,0kV - L/N-PE < 1,5kV I_{max} (8/20): 6,5 kA Fuse: T6,3AH/250 V SPD according to EN 61643-11: Typ3 Consumption overvoltage protection: < 0,1 W</p>		
 <p>(similar illustration)</p>		
Item-No. 0606x00052031 EAN 401209600600 8 PU10		458 x 65 x 43 mm Dimensions (L x B x H) 452 mm Fixing Dimension