


## Features

- UL approved Nylon 66, 94V-2
- Color: Natural, other special color available.
- Suitable for a multitude of uses including binding components or cable.
- Easy to thread.
- Cable ties are cheap, easy to use and strong.

## RS PRO Bead Cable Ties

RS Stock No.: 479594

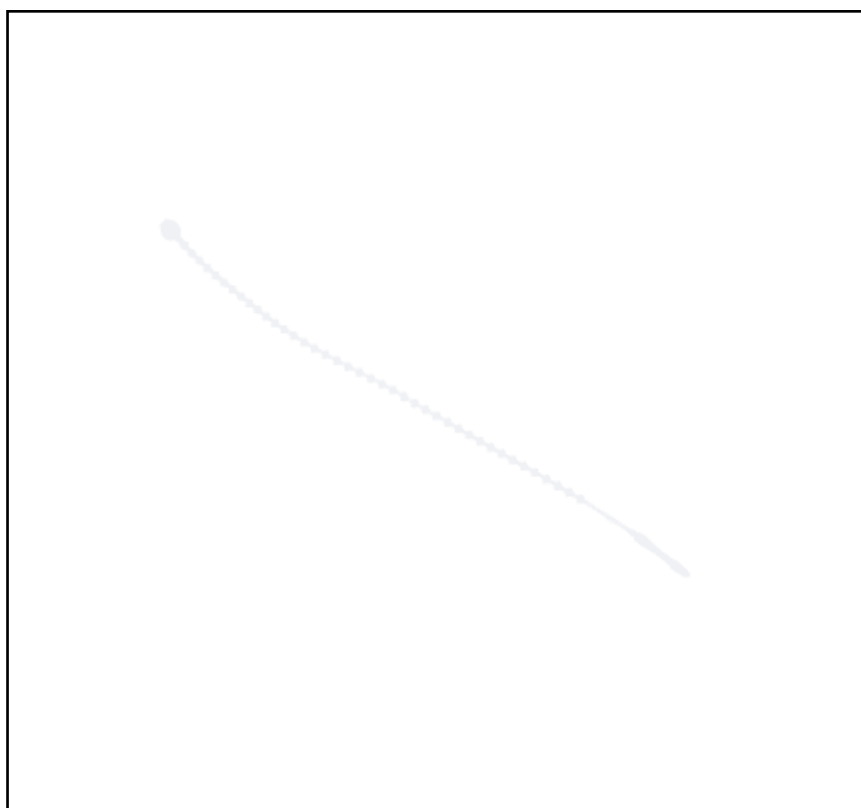

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

RS PRO beaded cable ties are a type of fastener used for holding items together, most commonly electrical cables or wires. These cable ties are made from Nylon 66 (also known as nylon 6.6) and are a one-piece, self-locking fastener that functions like straps to keep cables tidy. The unique beaded structure keeps wires from shifting or slipping and they have been designed to show at a glance if tampering has occurred, but in an emergency situation, breakaway as required. Ideal for cable and wire management for lightweight applications.

## General Specifications

Type	Non-releasable Cable Tie
Colour	Natural
Material	Nylon 66
UV Resistant	No
Fire Behaviour	Self-Extinguishing
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	85°C
Quantity	500

## Mechanical Specifications

Length	143mm / 5-3/8"
Width	1.8mm / 0.07"
Min. Loop Tensile Strength(lbs/kgf/N)	11lbs / 5kgf / 50N
Maximum Bundle Dia.	35mm

## Approvals

Standards Met	RoHS, SVHC, HF
---------------	----------------

