
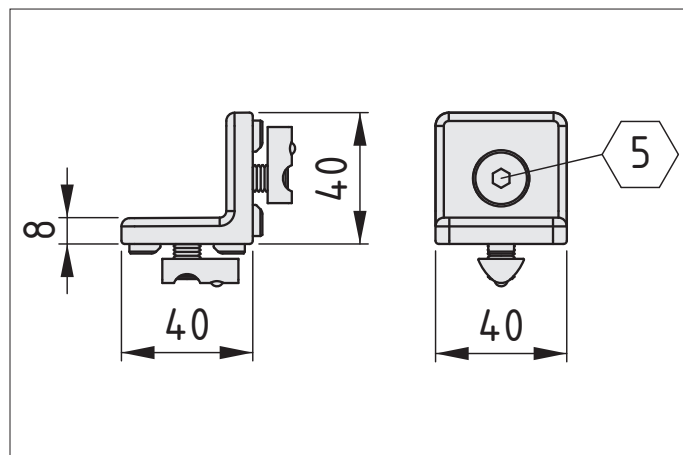


Angle Bracket 2V 8 40

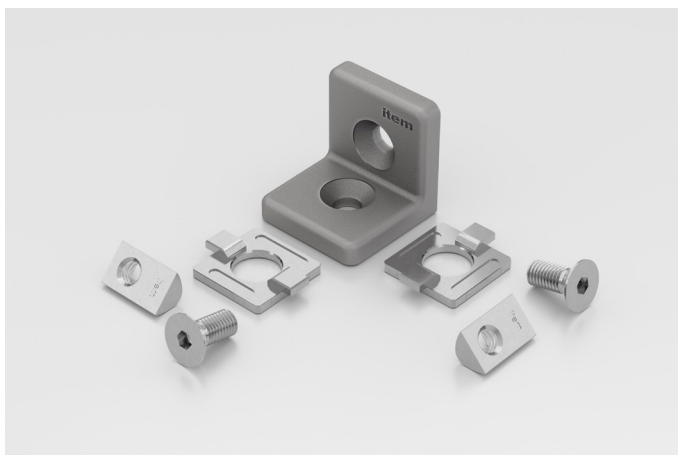

Angle Bracket 2V 8 40 features two inserts with anti-torsion features. It can be used to create right-angled and crossing profile connections with no need for additional machining. This metal bracket can also be used to fasten panel elements to profiles.

The inserts can be fitted in 90° increments and reversed. This ensures the anti-torsion features can be positioned to match the alignment of the profile groove. Reversing the insert creates a flat surface.

Scope of Delivery

- 1 Angle Bracket, die-cast Al, natural
- 2 inserts, die-cast zinc, bright zinc-plated
- 2 T-Slot Nuts 8 St M8, St, bright zinc-plated
- 2 Countersunk Screws DIN 7991 M8x18, St, bright zinc-plated

Technical note

[0.0.718.23](#) Please click here for further information!

Properties	
Article number	0.0.718.23
Delivery unit	1 set
Weight	101.0 g
Torque	25 Nm

Accessoires	
0.0.026.29	Key with T-Handle 5 A/F