

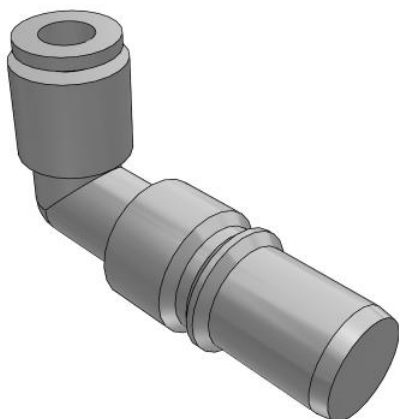
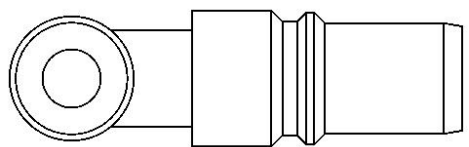


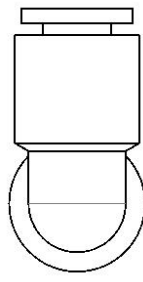

KK*P-*L, S-Couplers, Elbow Type with One-touch Fitting KK4P-06L

- Elbow Type with One-touch Fitting.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Tubing O.D.: Ø3.2, Ø4, Ø6, Ø8, Ø10, Ø12, Ø16.

Body Size	4 (1/4)
Applicable Tubing O.D.	Ø6 mm
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Effective Area	39 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant

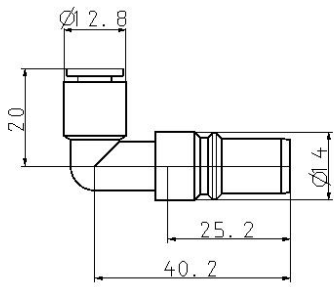

-
-

KK-C_EU.pdf