


Geberit Mapress Stainless Steel T-piece, equal (FKM, blue)



Example image

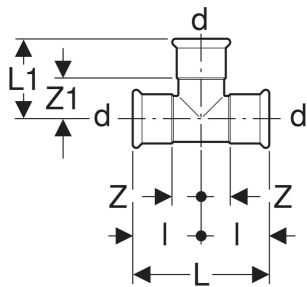

APPLICATION PURPOSES

- For chemicals and technical liquids
- For district heating water ≤ 140 °C
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)

- For compressed air (oil purity class 0–4)
- For solar technology, industry and shipbuilding
- For industrial gases (e.g. acetylene, shielding gases)

- Silicone-free (LABS-free)
- Seal ring made of FKM, blue
- Pressing socket with black protection plug

CHARACTERISTICS

- Pressing indicator

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	arc °	L cm	L1 cm	I cm	Z cm	Z1 cm
50332	12	15	90	6.4	3.9	3.2	1.2	1.9
50333	15	18	90	6.8	4.1	3.4	1.4	2.1
50334	20	22	90	7.4	4.4	3.7	1.6	2.3
50335	25	28	90	8.4	5	4.2	1.9	2.7
50336	32	35	90	10	5.7	5	2.4	3.1

Art. no.	DN	d, ø mm	arc °	L cm	L1 cm	I cm	Z cm	Z1 cm
50337	40	42	90	11.4	6.5	5.7	2.7	3.5
50338	50	54	90	13.8	7.7	6.9	3.4	4.2
50341	65	76.1	90	23	11	11.5	6.2	5.7
50342	80	88.9	90	26	12.7	13	7	6.7
50343	100	108	90	31	15.3	15.5	8	7.8