




ENGLISH

Datasheet

Stock No: 542-324

# RS Pro 34 x 27mm Hand Rectangular Punch & Die Combinations

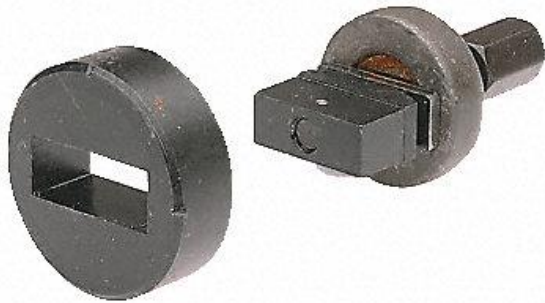

## Product Details

### Square, Rectangular and Radius Hole Cutters

Square, rectangular and radius (rounded corner) hole cutters suitable for use on mild steel (28 tons/in<sup>2</sup> uts max) up to 1.6mm (16 swg) and aluminium up to 2mm (14 swg) except as marked \* (in which case capacity is 18 swg/1.22mm mild steel)

Long life punches with minimum burr, distortion or surface damage

Easy to dismantle - slugs drop freely out of die

Most punches can be used with the hydraulic pump/cylinder Stock no [605-223](#) or hydraulic hand punch kit Stock no [388-3628](#) up to 35mm/1 1/4 in diameter (See comparison table for exceptions). Not suitable for lever presses

Ball race included

## Specifications:

Hole Shape	Rectangular
Operation	Hand
Hole Size	34 x 27mm
Cutting Capacity	Mild Steel: 1.6 mm; Aluminium: 2 mm