

➤ ZARGES
Eurobox



The Universal Box from ZARGES. Cleverly devised system accessories make it the best solution when it comes to packing, storage and transportation

- High-strength, corrosion-resistant aluminium alloy
- Stainless steel hinges
- Foam injected lid seal for protection against dust and spray
- Reinforcement beading
- Lid retention straps
- Lead seals for security, padlock (up to 6 mm shackle thickness) or lock installation upon request
- Safe central stacking
- Blue stacking corners made from impact-resistant plastic
- Ergonomic, heavy-duty, sprung, drop-type handles
- Highly robust with 3 fully-welded profile extrusions

Order No.	See No.	Internal dimensions (L×W×H, approx. mm)	External dimensions (L×W×H, approx. mm)	Capacity (approx. l)	Weight (approx. kg)
40 700	1	350 × 250 × 310 Special feature: Handle on lid	400 × 300 × 340	27	3.0
40 701	2	550 × 350 × 220 Special feature: 3 handles	600 × 400 × 250	42	4.7
40 702	3	550 × 350 × 310	600 × 400 × 340	60	4.9
40 703	4	550 × 350 × 380	600 × 400 × 410	70	5.2
40 704	5	750 × 350 × 310	800 × 400 × 340	81	6.1
40 705	6	750 × 550 × 380	800 × 600 × 410	155	7.5
40 706	7	750 × 550 × 580	800 × 600 × 610	240	8.9
40 709	8	1150 × 750 × 480 Special feature: 2 handles at each end	1200 × 800 × 510	415	13.0
40 710	9	1150 × 250 × 220 Special feature: 3 handles	1200 × 300 × 250	63	6.3

Inside width measurement approx. 30mm less than internal dimension

→ **Note:** lock not standard, please see accessories for Eurobox Pages 6 – 9.

Eurobox

Setting the Standard for Quality and Durability

ZARGES Eurobox



Order No. 40 707



Order No. 40 708

Eurobox (as described on page 3)
but with additional toolbox fittings

→ Aluminium corners internally for plastic inserts

Order No. 40 624/40 625

→ Armoured hasps for padlock
(up to 8 mm shackle thickness)

Order No.	Internal dimensions (L×W×H, approx. mm)	External dimensions (L×W×H, approx. mm)	Capacity (approx. l)	Weight (approx. kg)
40 707	550 × 350 × 310	600 × 400 × 340	60	5.5
40 708	750 × 350 × 310	800 × 400 × 340	81	6.7

Inside width measurement approx. 30 mm less than internal dimension

Combination Possibilities

Order No.	Plastic insert 40 625	Plastic insert 40 624
40 707	4 ×	-
	2 ×	3 ×
	-	6 ×
40 708	-	4 ×
	2 ×	1 ×

→ **Note:** contents not supplied,
plastic inserts are accessories (see right)

Plastic inserts:

→ Made from blue PS, including 2 dividers,
to fit 40 707/40 708.



→ Size: 315 × 170 × 60 mm.

Order No. 40 624



→ Size: 515 × 155 × 60 mm.

Order No. 40 625

ZARGES Box

Stands alone when it comes to light alloy packaging



ZARGES



ZARGES
ZARGES Box



Order No. 40 861

Order No. 40 877

Order No. 40 862

Order No. 40 863

Tools or sensitive equipment, service and assembly equipment, important documents or valuable components – a ZARGES box will literally provide storage for everything. Secure, stylish and safe.

- High-strength, corrosion-resistant aluminium alloy
- Protection against dust and spray
- Stainless steel hinges
- Peripheral foam injected lid seal
- Snaplocks with key-operated lock
- Spring-loaded plastic-coated drop-type handles
- Self-stabilising lids
- Highly robust with 3 fully-welded profile extrusions

Order No.	Internal dimensions (L×W×H, approx. mm)	External dimensions (L×W×H, approx. mm)	Capacity (approx. l)	Weight (approx. kg)
40 861 Mini-Box Front-mounted handle	550 × 350 × 220	600 × 400 × 240	42	4.0
40 877 Mini-Box „Plus“	550 × 350 × 310	600 × 400 × 330	60	4.5
40 862 Midi-Box	750 × 350 × 310	800 × 400 × 330	81	5.5
40 863 Maxi-Box	850 × 450 × 350	900 × 500 × 370	135	6.9

Inside width measurement approx. 30 mm less than internal dimension

→ **Note:** For accessories for ZARGES Box see Pages 6 – 9

Eurobox and ZARGES Box – Standard Accessories

Attaché Case Insert

→ Made from hard-wearing woven fabric. The practical briefcase for documents and working equipment

→ Size: 430 × 290 mm.

→ **Order No. 40 626**

To fit Eurobox: 40 701 to 40 706, 40 709

To fit ZARGES Box: 40 861 to 40 863, 40 877



Divider Set


→ Made from quality foam. The individual organiser for larger items.

→ Size: 550 × 350 × 190 mm.

→ **Order No. 40 730**

To fit Eurobox: 40 701 to 40 703

To fit ZARGES Box: 40 861, 40 877

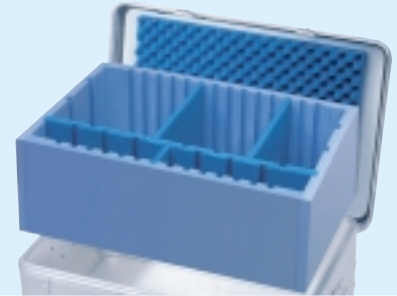

Toolbag

→ Detachable, made from hard-wearing woven fabric. The transportable storage bag for tools.

→ Size: 435 × 260 mm.

→ **Order No. 40 627**

To fit Eurobox: 40 701 to 40 706, 40 709

To fit ZARGES Box: 40 861 to 40 863, 40 877



Aluminium Divider Set

→ Consisting of one aluminium divider and two slotted panels. For even better organisation.

→ Set 1: **Order No. 40 864**

To fit Eurobox: 40 701

To fit ZARGES Box: 40 861

→ Set 2: **Order No. 40 865**

To fit Eurobox: 40 702 to 40 704

To fit ZARGES Box: 40 877, 40 862

→ Set 3: **Order No. 40 866**

To fit ZARGES Box: 40 863



Storage Box for Small Parts

→ Complete with 21 divider inserts made from PP. Systematic organisation for small items.

→ Size: 430 × 330 × 60 mm.

→ **Order No. 40 628**

To fit Eurobox: 40 701 to 40 704

To fit ZARGES Box: 40 861 to 40 863, 40 877



Lock Set

→ Consisting of two locks and two keys

→ One key operates all locks within the set only

Order No. 40 830

→ One key operates all locks within entire series

Order No. 40 831

To fit all Euroboxes and Rollboxes:

40 851, 40 852

Series with ZARGES Box





W 150 Dolly Trolley

→ Aluminium frame with two fixed and two swivel castors for smooth running. Ø 125 mm, 40 mm wide, rubber tyres, "non-marking" roller bearings.

→ **Order No. 40 607**

To fit Eurobox: 40 701 to 40 703, 40 707

To fit ZARGES Box: 40 861, 40 877

To fit K270 Transport Basket: 40 554, 40 555

→ **Order No. 40 608**

To fit Eurobox: 40 705, 40 706

To fit K270 Transport Basket: 40 551 to 40 553



Add-on Castors

→ Made from quality polyamide. Load capacity up to 50 kg. Supplied with all fixings and instructions for assembly, easy to fit.

→ **Order No. 40 738**

To fit: all Euroboxes and all ZARGES Boxes



Trolley

→ Simple self-assembly, smooth-running under-carriage, castors Ø 54 mm, load capacity 40 kg. The "Extendable" handle can be locked in position.

→ **Order No. 40 739**

To fit Eurobox: 40 701 to 40 708

To fit ZARGES Box: 40 861, 40 862, 40 877

→ Additional set enables trolley to be used with other boxes

Order No. 40 740

W 152 Dolly Trolley

→ Aluminium frame with two fixed and two swivel castors, for smooth running. Ø 125 mm, 40 mm wide, rubber tyres, "non-marking" roller bearings. H = 450 mm

→ **Order No. 40 680**

To fit Eurobox: 40 705, 40 706

To fit K270 Transport Basket: 40 551 to 40 553

→ **Order No. 40 609**

To fit K250 Transport Basket: 40 781, 40 782




Eurobox and ZARGES Box – Accessories

For individual transport solutions

Pick 'n Pluck Foam Set

- Pre-cut soft foam inserts made from open-cell PU foam, the fast and cost-effective solution for individual pieces or low-volume batch production. Sheet thickness in set, 2 each 30 mm and 60 mm, raised foam finish lid insert 30 mm, base foam 10 mm. Including adhesive. Lid insert foam with raised finish, shape can be modified without the need for special tools.
- Set 1: 550 × 350 × 220 mm.
Order No. 40 735
To fit Eurobox:
40 700 (cutting to size required) up to 40 703
To fit ZARGES Box: 40 861, 40 877
- Set 2: 750 × 550 × 220 mm.
Order No. 40 736
To fit Eurobox: 40 704 (cutting to size required) up to 40 706
To fit ZARGES Box: 40 862 (cutting to size required)
- Set 3: 1150 × 250 × 220 mm.
Order No. 40 737
To fit Eurobox: 40 710

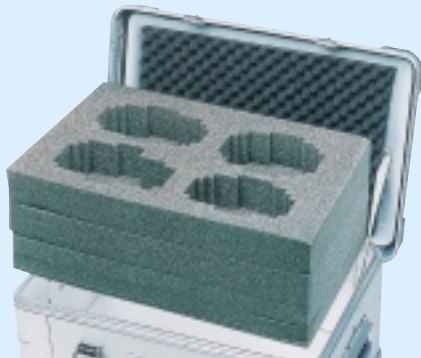


Foam Inserts

- If required we can supply the Euroboxes with a durable and abrasion-resistant PE foam lining. Floor and side-panels made from Plastazote LD 45 (weight per unit volume 45 kg/m³, thickness 11 mm). Lid lined with foam with raised finish.
- Other materials and side panel thicknesses can be supplied on request.



Individual Foam Inserts

- We manufacture customised padded inserts from a wide range of materials which, in terms of protection and functionality, are perfectly suited to the goods you wish to transport.
- One of the special features of these first-class foam inserts is the fact that the protective effect of the finished packaging can be calculated in advance.
- Taking into account weight, area, height of drop and sensitivity (G-value), we develop packaging for you featuring optimum padding thickness. The result is maximum protection with minimum raw materials usage.
- If required, antistatic fittings and dissipative inserts are also available.

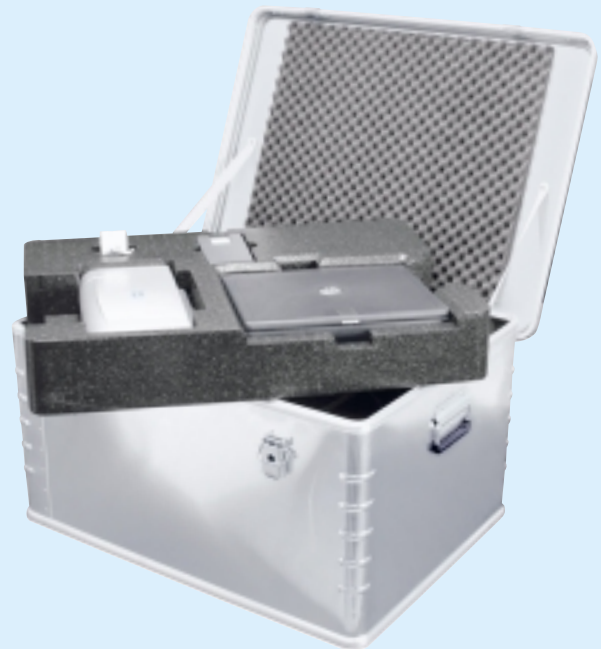

Contents not supplied

Eurobox and ZARGES Box – Accessories

Possible combinations



What goes where ?

(Internal dimensions, L×W in approx. mm)

Order No.	Description	350 × 250 mm	550 × 350 mm	750 × 350 mm	750 × 550 mm	850 × 450 mm	1150 × 250 mm	1150 × 750 mm
40 626	Attaché case	-	✓	✓	✓	✓	-	✓
40 627	Tool bag	-	✓	✓	✓	✓	-	✓
40 628	Box for small items	-	✓	✓	-	✓ ²⁾	-	-
40 730	Divider panel set	-	✓	-	-	-	-	-
40 735	Pick 'n Pluck foam set 1	✓ ¹⁾	✓	-	-	-	-	-
40 736	Pick 'n Pluck foam set 2	-	-	✓ ¹⁾	✓	-	-	-
40 737	Pick 'n Pluck foam set 3	-	-	-	-	-	✓	-
40 864	Aluminium divider panel set 1	-	✓	-	-	-	-	-
40 865	Aluminium divider panel set 2	-	✓	-	-	-	-	-
40 866	Aluminium divider panel set 3	-	-	-	-	✓	-	-
40 607	W150 dolly trolley	-	✓	-	-	-	-	-
40 608	W150 dolly trolley	-	-	-	✓	-	-	-
40 680	W152 dolly trolley	-	-	-	✓	-	-	-
40 738	Add-on castors	-	-	✓	✓	✓	✓	-
40 739	Trolley	-	✓	✓	✓	-	-	-
40 830	Lock set, One key operates all locks within set	✓	✓	✓	✓	✓	✓	✓
40 831	Lock set, One key operates all locks within entire series	✓	✓	✓	✓	✓	✓	✓

¹⁾ Cut to size

²⁾ 2 Boxes possible

System Accessories Combinations

ZARGES Eurobox	Attaché Insert	Toolbag	Divider Set	Pick 'n Pluck Foam Set	Small Items Box
Attaché Insert	-	No	Yes	Yes	No
Toolbag	No	-	Yes	Yes	No
Divider Set	Yes	Yes	-	No	Yes
Pick 'n Pluck Foam Set	Yes	Yes	No	-	Yes
Small Items Box	No	No	Yes	Yes	-

Note: Accessory combinations dependent on box heights

It may be necessary to shorten, e.g. parts of the divider panel set or to omit a Pick 'n Pluck foam set location



Whether it's the North Pole or the Equator ...



... ZARGES boxes are eminently suitable for each and every application.