



Brand of NTN corporation

## Technical data

### ESEHE.205

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, single lip seal

### KIT CONTENT

ES205G2, EHE205

### VISUAL (S)

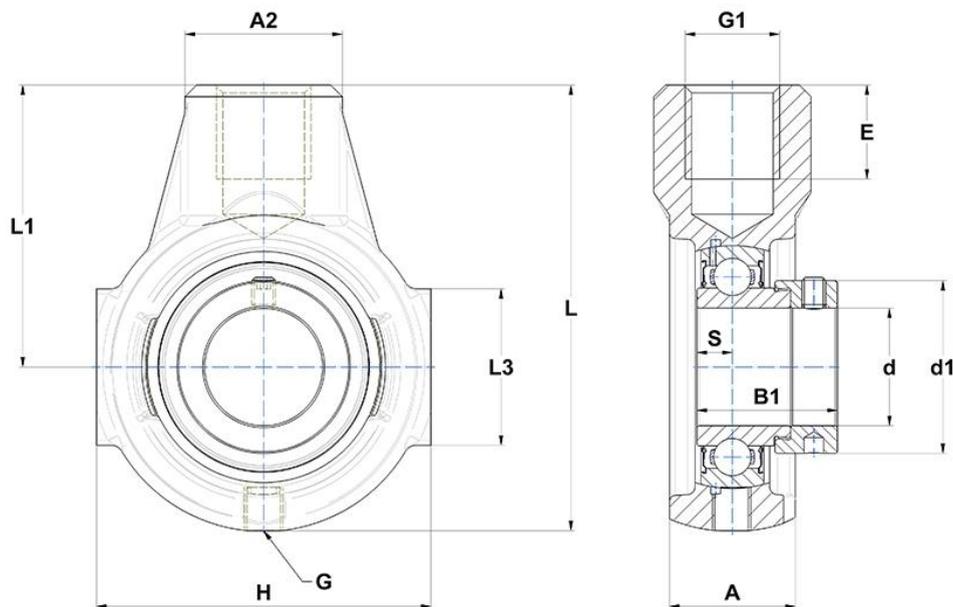

### PRODUCT DEFINITION

<b>Brand</b>	SNR
<b>A - Housing width</b>	28 mm
<b>A2</b>	35 mm
<b>B1 - Overall width Inner Ring</b>	30,9 mm
<b>d - Shaft diameter</b>	25 mm
<b>d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve</b>	37,4 mm



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

### PRODUCT DEFINITION

<b>E - Mounting hole thread depth</b>	22 mm
<b>G - Grease fitting</b>	R1/8"
<b>G1 - Thread size</b>	M20
<b>H - Housing length, width or diameter</b>	70 mm
<b>L - Housing length</b>	99 mm
<b>L1 - Distance attachment end face to bearing centerline</b>	64 mm
<b>L3 - Length of guidance slot/face</b>	38 mm
<b>S - Distance front side/bearing centre</b>	7,5 mm

### PRODUCT PERFORMANCE

<b>C - Dynamic load rating</b>	14000000 mN
<b>C0 - Static load rating</b>	7880000 mN
<b>Operating temperature min.</b>	253,15 °K
<b>Operating temperature max.</b>	373,15 °K

### OTHER FEATURES

<b>Mass</b>	0,69 kg
<b>Recommended tightening torque for set screw</b>	5.5 N-m

