



light source

LED

Energy efficiency category A/A+/A++

electronic transformer

100-240 V; 50/60 Hz

approx. 34 W

approx. 1800 lm

approx. 52 lm/W

neutral white, approx. 4000 K

>= 80

IP20

I

multi-function switch

sectional aluminium, anodised, aluminium coloured anodised

polycarbonate, white opal

aluminium coloured anodised

spring

approx. 2.3 kg

approx. 3,4 m; mains plug

CEE 7/VII

screw-down flange, table clamp (accessory), wall bracket (accessory)

Ra (luminaire) ca. 90

work equipment connected load

Power consumption

luminous flux

luminous efficacy

colour temperature

color rendering index (CRI)

System of protection

class of protection

operation

luminaire body

lamp cover

tubular sections

balance of articulation joints

weight (net)

mains lead

Fastening

special features




CEE 7/VII

illuminance

distance: 50 cm

Em: 1082 lx
Emax: 2219 lx
Emin: 348 lx

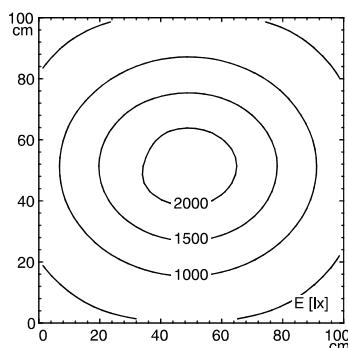

luminous intensity

