

IP20 FLEXIBLE LED TAPE +FLEX 208 HIGH CRI



12.7W/M



up to
1796LM/M



IP20



Recycleable
Cardboard



>95Ra



2700K, 3000K
4000K, 6000K



38.45mm
Cut Points



FEATURES

- High CRI >95Ra
- Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Working temperature -20°C - +45°C
- Humidity 40% - 70% RH
- 3 years warranty

SPECIFICATIONS


Stock Code	0615-165	0337-322	1111-381	1422-953
Part Code	B7-2-208-20-95	C0-2-208-20-95	D0-2-208-20-95	F0-2-208-20-95
Voltage	24VDC	24VDC	24VDC	24VDC
Power Consumption	12.7W/M	12.7W/M	12.7W/M	12.7W/M
Lumen Output	1701LM/M	1746LM/M	1796LM/M	1796LM/M
Efficacy	134LM/W	137LM/W	141LM/W	141LM/W
Tone (CCT)	2700K ●	3000K ●	4000K ●	6000K ●
LED/metre	208	208	208	208
LED Pitch	4.81mm	4.81mm	4.81mm	4.81mm
Cut Points	38.45mm	38.45mm	38.45mm	38.45mm
CRI	>95Ra	>95Ra	>95Ra	>95Ra
IP Rating	20	20	20	20
Dimensions	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm




2700K



3000K

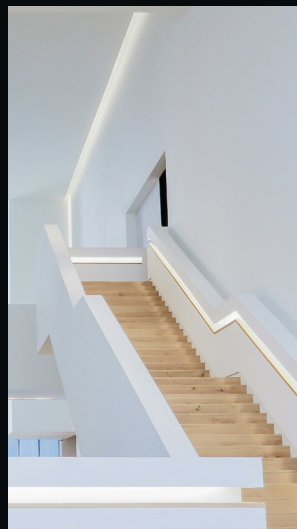

4000K

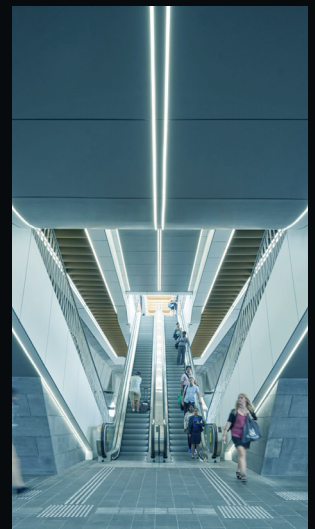

6000K

IP20 FLEXIBLE LED TAPE +FLEX 208 HIGH CRI



COMPATIBILITY



CONTROL METHODS

- Bluetooth (Apps, Voice Control) - BLE-15A
- Remote Control - SCD107W

SUGGESTED DRIVERS

Up to 1 M	Up to 5 M	Up to 10 M
Power supplied from ONE end	Power supplied from ONE end	Power supplied from the MIDDLE or BOTH ends
Non Dimmable	Non Dimmable	Non Dimmable
PCV2420	PCV2475	PCV24151
Mains Dimmable	Mains Dimmable	Mains Dimmable
UVC2425TD	UVC24100TD	UVC24200ETD
DALI Dimmable	DALI Dimmable	DALI Dimmable
DA-30-24	DA-75-24	ELG-150-24DA

*Other options available. Contact us for more information.

MECHANICAL DIAGRAM

