


KEMET Part Number: SHBC8S-0R6A0067V
(UALS8S0R6A0067)

KEMET, SHBC, AC Line Filters, Normal Mode, 67 uH, 20%

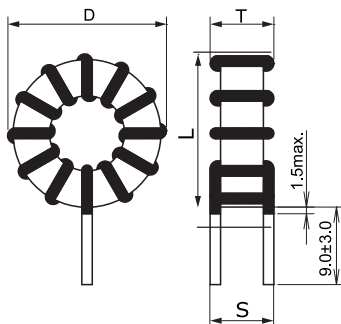

Dimensions

D	17mm MAX
L	17mm MAX
T	17mm MAX
LL	9mm +/-3mm
S	7.5mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	700
Weight:	4 g

General Information

Series:	SHBC
Style:	Through-Hole
Features:	Low Core Loss, High Frequency Drive
RoHS:	Yes
Miscellaneous:	25 (K) Temperature Rise Max.

Specifications

Inductance:	67 uH
Inductance Tolerance:	20%
Current:	2 A
Temperature Range:	-40/+125°C
DC Resistance:	67.8 mOhms