
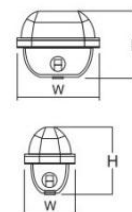


Data Specification Sheet

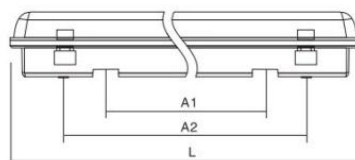

230V T5 IP65 Fluorescent Fittings

Description	IP65 T5 230V High Frequency Fluorescent Fitting							
Base Finish	Grey							
Product Code	851-2918	851-2927	851-2924	851-2920	851-2933	851-2936	851-2949	851-2930
Length mm	610	1210	1510	1510	610	1210	1510	1510
Width mm	65	65	65	65	104	104	104	104
Height mm	75	75	75	75	75	75	75	75
A1 mm	316	672	780	780	316	672	780	780
A2 mm	372	795	960	960	372	795	960	960
Wattage (W)	14	28	35	35	2x14	2x28	2x35	2x35
Circuit Watts	14.5	29	37	38	30	66	75.5	76
Typical location	Indoor or Outdoor							
Lamp Supplied	No							
Voltage (V)	230V 50Hz							
Class	Class I. Must be Earthed							
IP	IP65							
Photometric Testing	Yes							
Instruction sheet	Yes							
Origin of manufacture	China							
Pack Included	Polycarbonate clips. Fixing brackets 20mm compression gland.							
Main materials:								
• Body	Polycarbonate							
• Diffuser	Polycarbonate							
• Gear Tray	Pressed Steel powder coated white							
• Clips	Polycarbonate (security type) Stainless Steel (Optional, RS Stock No. 851-2942)							
• Gasket	Silicone Rubber							
Method of fix	Speed fix stainless steel brackets (Supplied)							
Lamp holder cap	G5 / Kang Rong							
Lamp type	T5							
Electrical Connections	L.E.N. Nylon Connector, Screw Terminals							
Control gear	H.F. Electronic ballast Optional 3 hour Maintained (EM)							
Operating Temperature	- 20°C to +30°C							
Dimmable	No							
Cold Store Version -20°C	No							
CE mark	Yes							
Quality Assurance System	Yes ISO 9001 QMS							
Batch coding details	Yes							
Certificate of Conformity	Yes							
Manufactured in accordance	EN60 598-2-1							
Guarantee Period	1 Year							