

Pliers

Erem pliers, stripping pliers, forming pliers

- Gripping and bending pliers with standard and ergonomic handles
- MagicSense – moulded handle for increase comfort
- Wide variety of head shapes
- Special tool steel, non-reflecting surface, ESD-safe

Internal patented Erem Magic Spring


- Constant spring force
- Guarantees more than 1 million operations

High precision screw joint

- Smooth jaw action with no play
- Smooth cutting operation with no jaw overlapping

Precision ground jaws



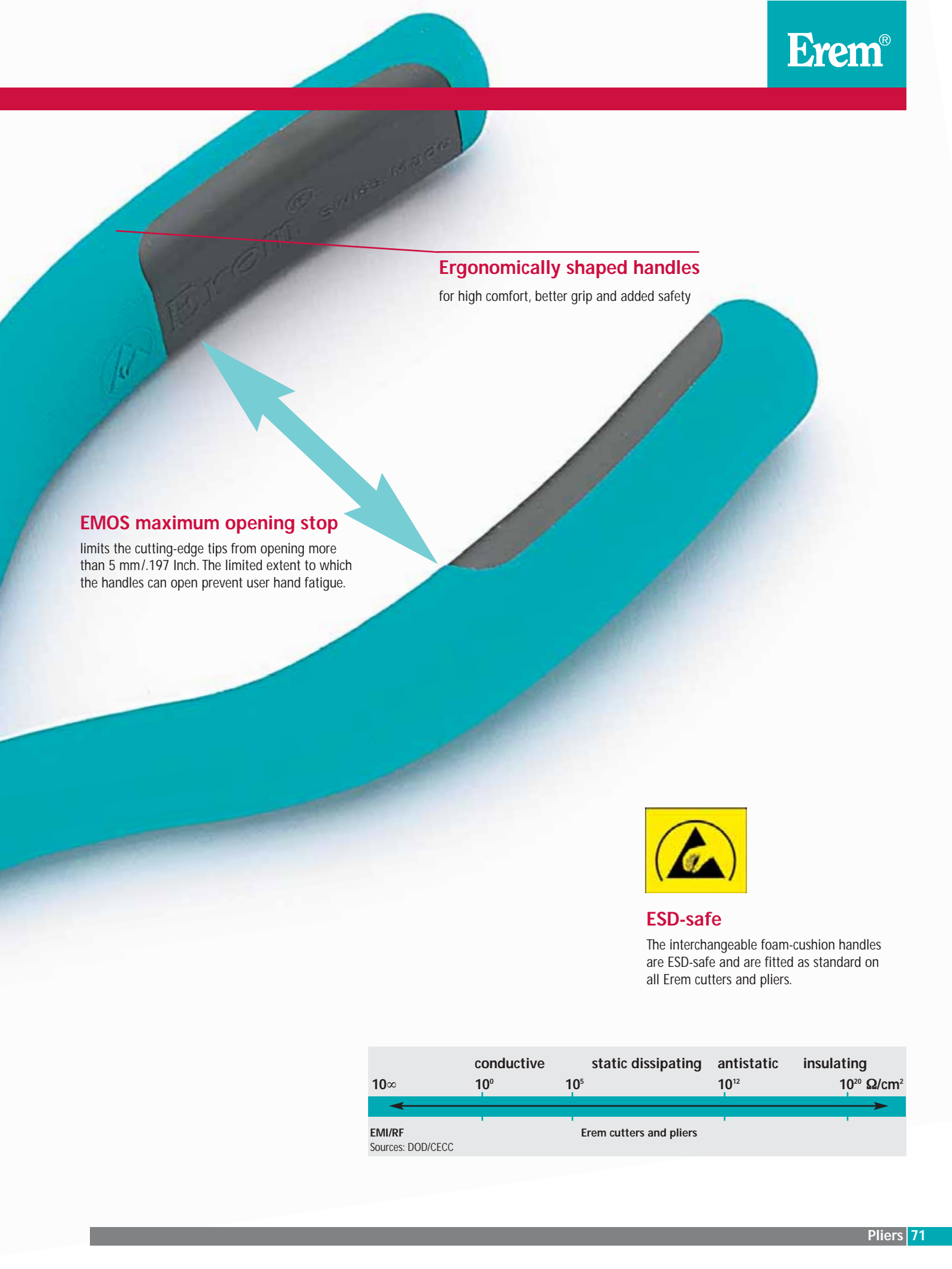

Ergonomically shaped handles

for high comfort, better grip and added safety


EMOS maximum opening stop

limits the cutting-edge tips from opening more than 5 mm/.197 Inch. The limited extent to which the handles can open prevent user hand fatigue.



ESD-safe


The interchangeable foam-cushion handles are ESD-safe and are fitted as standard on all Erem cutters and pliers.

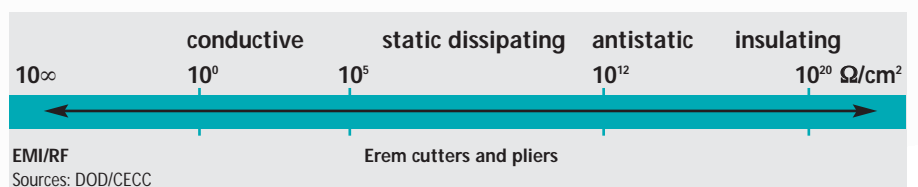

Pliers

Erem pliers

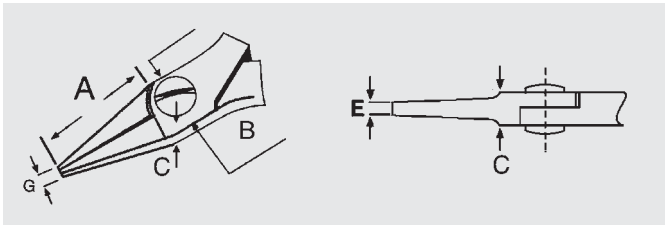

- Pliers for miniature and standard electronics
- Special tool steel, non-reflecting surface, ESD-safe
- High grade tool steel




- A = jaw length
- B = head width
- C = head thickness
- E = width of tips
- G = total height of both tips

Round nose pliers





 120 m/4.724 Inch
 62 g

- Round nose pliers with very precise, smooth jaws.
- Suitable for forming, bending, laying and feeding in wires.


Model	Shape	Dimensions in mm/Inch				
		A	B	C	E \varnothing	G
543E		23	9	6.5	0.8	1.6
		.905	.354	.256	.031	.062

Needle nose pliers



 120 m/4.724 Inch
 62 g

- Needle nose pliers with very precise, smooth and rounded jaws.
- Suitable for forming, bending, laying and feeding in wires.

Model	Shape	Dimensions in mm/Inch				
		A	B	C	E	G
547		23	9	6,5	0,9	1,2
		.905	.354	.256	.035	.047

Erem pliers

Flat nose pliers



120 m/4.724 Inch
 67 g

- Flat nose pliers with smooth jaws and precision-machined edges.
- Suitable for gripping flat workpieces.

Model	Shape	Dimensions in mm/Inch				
		A	B	C	E	G
542E		23	9	6.5	2.4	1.4
		.905	.354	.256	.094	.055



125 m/4.921 Inch
 67 g

- Flat nose pliers with replaceable nylon jaws.
- Nylon jaws prevent nicking and scratching.
- Suitable for forming precious metals and component connections.

Model	Shape	Dimensions in mm/Inch				
		A	B	C	E	G
531E		23	9	6.5	5	3
		.905	.354	.256	.197	.118

Chain nose pliers



120 m/4.724 Inch
 67 g

- Chain nose pliers with narrow half-round jaws.
- For securely handling components.

Model	Shape	Dimensions in mm/Inch				
		A	B	C	E	G
544E		23	9	6.5	1	1.4
		.905	.354	.256	.039	.055



125 mm/4.921 Inch
 67 g

Model	Shape	Dimensions in mm/Inch					
		A	B	C	E	G	
544D		23	9	6.5	1	1.4	Inside-serrated jaws for secure handling
		.905	.354	.256	.039	.055	