




ENGLISH

Datasheet

## RS Pro Steel Alloy Compression Spring, 15.7mm x 2.75mm, 0.22N/mm

RS Stock No: **751-360**

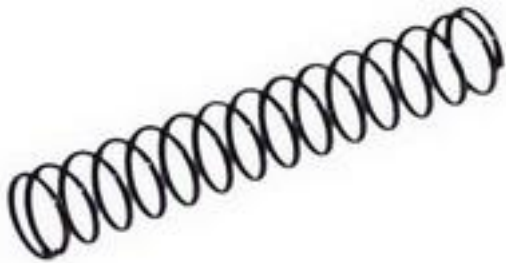

### Product Details

RS Pro stainless steel alloy compression spring measures 15.7 x 2.75 mm and has a spring rate of 0.22 N/mm. It handles a load of 2.31 N at a minimum working length of 5 mm. This spring features right hand helix construction.

### Features and Benefits

- Wire diameter ends up to 0.8 mm are squared and ungrounded
- Wire diameter ends 1 mm and over are squared and ground
- Manufactured with a right hand helix



**Specifications:**

Ends	Closed (Square)/Unground
Material	Steel Alloy
Free Length	15.7 mm
Load at Minimum Working Length	2.31 N
Minimum Working Length	5 mm
Outside Diameter	2.75 mm
Spring Rate	0.22 N/mm
Wire Diameter	0.25 mm