




ENGLISH

## Datasheet

# H05VVH8-F 3 Core Black Mains Power Cable, PVC Sheath, 1m Length

Stock number: 744-0988

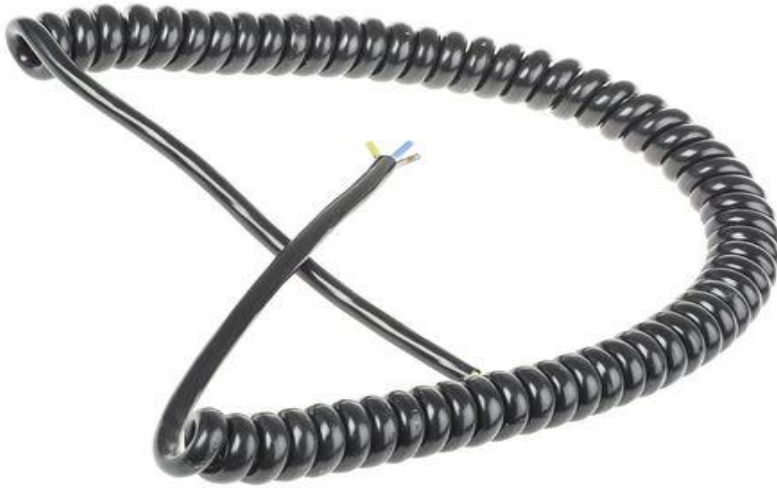

### Scope

This specification defines the characteristics of a three core coil cord for general power supply applications.

### Construction Details

		Diameter
Conductor	90/0.10mm Plain Annealed Copper per BS6360, Class 5	1.09mm
Insulation	PVC per BS6746 Colors: Blue, Brown, Yellow/Green	2.4mm
Cable	Three insulated conductors cabled together	
Jacket	PVC per BS6746 Color: Black	7.0mm
Jacket Print	"<HAR> 2011 H05VVH8-F COIL"	

### Properties

Temperature Rating	70°C
Current Rating	6.0 Amp

### Compliance

BS6500  
Cenelec Harmonized Type H05VVH8-F

**Coil Cord Dimensions**

Coil Dimension	24mm
Dimension A	150mm
Dimension B (Compressed)	420mm
Dimension B (Relaxed)	700-800mm
Dimension B (Stretched)	2200mm

Note: The relaxed dimension is taken after the cable has been stretched.

