



KCUIABDpm



KCUIA311whDSpm

KCHDDpm

KCK66Dpm

KOCMMDpm

KOCSMDpm



KOLMMDXDpm

KOLSMDXDpm

KOTMMDpm

KOTSMDpm

SKmcDpm



FACK2Dpm

SACK2Dpm

FACK2SDSpm

SACK3SDSpm

SGKSsu+DSpm



SGACK2SDSpm

SGACK902DSpm

SEKeiDSpm

KBNC50Dpm

KUA2bkDpm



KSPbkDpm



KSPrdDpm



SKFDpm



SGKSieDSpm



KSH66Dpm



KCFDpm



KGB1Dpm



KRCA*bkDpm



KC3.5bkDpm



SLJbkDpm



KBNC1275bk



SGKSLJDSpm



SGKctDpm



KADkpk



KADscrew R/F



SGACK90Dpm



SGKSbtDSpm



KADpmNL



KCUAB3Dpm



KUCC20Dpm



FFDU16/CM





MDUbK



KADSpNL

Requirements for cut-out:

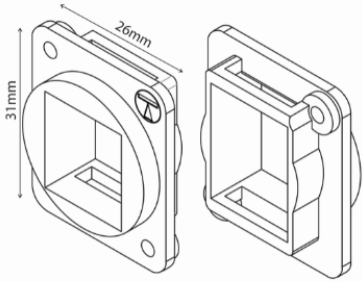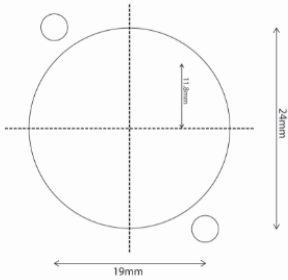

Front

Back

D Universal Adaptor

Code	Description
KCUABDpm	USB A female to B female adaptor, reversible
KCUAA2Dpm	USB2.0 A female to A female coupler
KCUAAXDpm	USB2.0 A female to A female coupler, either way insertion
KCUAA3bkDpm	USB3 female to female coupler, cross-wired
KCUAA311whDpm	USB3 female to female coupler, wired 1:1
KUCC20Dpm	USB C female keystone to C male tailed lead, 20cm tail
KCHDDpm	HDMI female to female coupler
KCK66Dpm	RJ12 6P6C female to female coupler
KOCMMDpm	Fibre female to female coupler SC to SC, multi mode simplex
KOCSMDpm	Fibre female to female coupler SC to SC, single mode simplex
KOLMMDXDpm	Fibre female to female coupler LC to LC, multi mode duplex
KOLSMDXDpm	Fibre female to female coupler LC to LC, single mode duplex
KOTSMDpm	Fibre female to female coupler ST to ST, single mode simplex, yellow dustcover
KOTMMDpm	Fibre female to female coupler ST to ST, multi mode simplex, black dustcover
SKmcDpm	Category 6 IDC socket, LSA-Plus and 110 type termination, unshielded
KCUAB3Dpm	
FACK2Dpm	Category 5e female to female coupler, unshielded
SACK2Dpm	Category 6 female to female coupler, unshielded
FACK2SDSpm	Category 5e female to female coupler, shielded
SACK3SDSpm	Category 6 female to female coupler, shielded
SGKSsu+DSpm	Category 6A tool-less socket, shielded
SGKSbtDSpm	Category 6A tool-less socket, shielded contractor grade
SGACK2SDSpm	Category 6A female to female coupler, shielded
SGACK902DSpm	Cat 6A female to female coupler, w/rear outlet 90° to front outlet, shielded
SGACK90Dpm	Cat 6A female to female coupler, w/rear outlet 90° to front outlet, unshielded
SEKeiDSpm	Category 8 tool-less socket, shielded
KBNC50Dpm	BNC 50 ohm female to female coupler
KSPbkDpm	Speaker module in black with black elastic identifier
KSPrdDpm	Speaker module in black with red elastic identifier
SKFDpm	Category 6 tool-less IDC socket, unshielded (Category 5e also available)
SGKSjeDSpm	Category 6A Shielded Keystone Jack
KSH66Dpm	RJ12 6p6c socket, LSA-Plus termination
KCFDpm	F connector, female to female, coupler
KGB1Dpm	UK telephone socket - PSTN Master (Slave/Secondary version also available)
KRCA*bkpm	RCA coupler - available with black/white/yellow/red insert
KC3.5bkDpm	3.5mm coupler
SLJbkDpm	LOKJAC Category 6 tool-less locking keystone
KBNC1275bkDpm	BNC coupler Ultra HD 75 ohm 12Ghz
SGKctDpm	Category 6A tool-less UTP socket
KADkpk	D UNIVERSAL blank, black
KADscrew R/F	M3 screw to fit standard panels (length: 10mm), in bag of 50 pieces; roundhead or flathead, black
MDUbK	Metal and fire resistant D UNIVERSAL blank, black
FFDU16/CM	D UNIVERSAL XLR type 16 port panel / with cable management

*: Black = bk, Red = rd, Yellow = yw, White = wh

TUK's D UNIVERSAL series of connectors offers a wide variety of audio, video and data connectors all available for use in standard 'D Series' XLR type cut-outs. Designed for rear mounting, our connectors have a pleasing flush appearance when mounted in suitable panels. All items in the range can be mounted quickly without need for any securing nuts, as our PATENTED 26 x 31mm mounting plates (made from black polycarbonate or nickel plated PC/ABS according to connector type) are prethreaded for M3 screws. All connectors are made to relevant standards. Category 6 and 6A connectors are produced, for example, to FCC68 and to TIA/EIA 568B and have an insertion life of >750 mating cycles. All products are CE compliant (ie including ROHS and REACH) TUK seeks continuously to expand the range to ensure comprehensive coverage of established and new voice, A/V and data cabling technologies

Specifications:

- Each connector supplied as a kit comprises of connector and D UNIVERSAL adaptor (KADpm or KADSpM)
- For specifications of couplers and sockets, see separate web pages as follows:

USB A female to B female coupler: <https://tuk.co.uk/product/usb-a-female-to-b-female-keystone-coupler/>

USB2.0 A female to A female: <https://tuk.co.uk/product/usb-2-0-a-female-to-a-female-keystone-coupler/>

USB2.0 A female to A female, reversible:

USB3 female to female coupler, cross-wired: <https://tuk.co.uk/product/usb3-female-to-female-keystone-coupler-cross-wired/>

USB3 female to female coupler, wired 1:1: <https://tuk.co.uk/product/usb3-female-to-female-keystone-coupler-wired-1-1/>

USB3 A female to B female coupler: <https://tuk.co.uk/usb3-a-female-to-b-female-keystone-coupler>

USB3.2 USB C female keystone to C male tailed lead, 20cm tail <https://tuk.co.uk/product/usb3-2-c-female-keystone-to-male-c-lead>

HDMI female to female coupler: <https://tuk.co.uk/product/hdmi-female-to-female-keystone-coupler/>

RJ12 female to female coupler: <https://tuk.co.uk/product/contractor-grade-rj12-6p6c-keystone-coupler/>

Fibre female to female couplers: <https://tuk.co.uk/product/fibre-keystone-coupler/>

Cat 6 IDC UTP jack: <https://tuk.co.uk/product/category-6-component-level-keystone-socket/>

Cat 5e UTP and FTP female to female coupler: <https://tuk.co.uk/product/category-5e-shielded-keystone-panel-mount-coupler/>

Cat 6 UTP and FTP female to female coupler: <https://tuk.co.uk/product/category-6-keystone-coupler-shielded/>

Cat 6A FTP jack: <https://tuk.co.uk/product/shielded-keystone-jack-category-6a/>

Category 6A socket, shielded contractor grade: <https://tuk.co.uk/product/contractor-grade-category-6a-shielded-keystone-socket/>

Cat 6A FTP female to female coupler: <https://tuk.co.uk/product/category-6a-shielded-keystone-coupler/>

90° Cat 6A shielded female to female coupler: <https://tuk.co.uk/product/90%cb%9a-shielded-keystone-panel-mount-coupler-category-6a/>

90° Cat 6A unshielded female to female coupler: <https://tuk.co.uk/product/90%cb%9a-keystone-panel-mount-coupler-category-6a-2/>

Cat 8 FTP jack: <https://tuk.co.uk/product/category-8-shielded-keystone-socket/>

BNC 50 ohm female to female coupler: <https://tuk.co.uk/product/bnc-keystone-coupler-50-ohm/>

Speaker module: <https://tuk.co.uk/product/keystone-speaker-connector/>

Cat 5e and Cat6 tool-less UTP socket: <https://tuk.co.uk/product/keystone-socket-tool-less-category-6/>

Cat 6A tool-less STP socket: <https://tuk.co.uk/product/category-6a-shielded-keystone-socket/>

RJ12 6p6c socket: <https://tuk.co.uk/product/rj12-6p6c-keystone-socket/>

F connector female to female coupler: <https://tuk.co.uk/product/f-connector-female-to-female-keystone-coupler/>

UK telephone socket: <https://tuk.co.uk/product/uk-telephone-keystone-master-or-secondary-socket/>

RCA coupler: <https://tuk.co.uk/product/rca-keystone-coupler/>

3.5mm coupler: <https://tuk.co.uk/product/3-5mm-keystone-coupler/>

LOKJAC Category 6 tool-less locking keystone: <https://tuk.co.uk/product/lokjac-category-6-tool-less-locking-keystone/>

BNC keystone coupler Ultra HD 75 ohm 12Ghz: <https://tuk.co.uk/product/bnc-keystone-coupler-ultra-hd-75-ohm-12ghz/>

Cat 6A Tool-less UTP socket: <https://tuk.co.uk/product/category-6a-utp-toolless-keystone-socket/>

D UNIVERSAL blank: <https://tuk.co.uk/product/d-universal-blank/>

D UNIVERSAL XLR type 16 port panel: <https://tuk.co.uk/product/d-universal-xlr-type-16-port-panel/>

13th November 2024

TUK Ltd, Unit 4, Wimbledon Stadium Business Centre, Riverside Road, London SW17 0BA