



Heat Shrinkable Cable Repair Sleeves

RMS

RMS wrap-around sleeves are easy to install.

Features and Benefits

- Fast, moisture proof and permanent repair of cable jackets
- Only 6 sizes for a wide range of cable diameters: from 10 mm up to 160 mm
- Available in 4 standard lengths, custom lengths available on request
- Each RMS kit is ready for use and comes with instruction sheet, abrasive strip and cleaning sachet
- Weather resistant and halogen free
- TCP (thermo-chromatic paint) spots indicate the sleeve has been sufficiently heated



Application video: RMS




RMS wrap-around sleeves for rapid and secure cable repair on site.

MATERIAL	Polyolefin, Chemically cross-linked (PO-X)
Shrink Ratio	up to 4.5:1
Operating Temperature	-40 °C to +120 °C
Minimum Shrink Temperature	+110 °C
Softening Point Adhesive	+105 °C
Longitudinal change after shrinkage	-10 % max.
Dielectric Strength	30 kV/mm
Flammability	not flame retarded



RMS: Repair sleeve, steel closure, abrasive strip, cleaning sachet, instruction sheet.

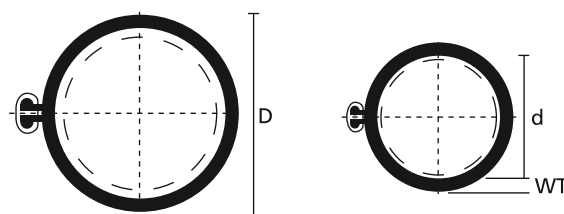

Cable Repair Sleeve RMS with adhesive

TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Suitable for Cable Ø from/to	Length (L)	Colour	Article-No.
RMS 43-10	43	10.0	2.30	15 - 35	250.0	Black (BK)	450-20000
	43	10.0	2.30	15 - 35	500.0	Black (BK)	450-20001
	43	10.0	2.30	15 - 35	750.0	Black (BK)	450-20004
	43	10.0	2.30	15 - 35	1,000.0	Black (BK)	450-20002
RMS 52-15	52	15.0	2.30	20 - 45	250.0	Black (BK)	450-20010
	52	15.0	2.30	20 - 45	500.0	Black (BK)	450-20011
	52	15.0	2.30	20 - 45	750.0	Black (BK)	450-20014
	52	15.0	2.30	20 - 45	1,000.0	Black (BK)	450-20012
RMS 76-22	76	22.0	2.50	28 - 65	500.0	Black (BK)	450-20021
	76	22.0	2.50	28 - 65	750.0	Black (BK)	450-20024
	76	22.0	2.50	28 - 65	1,000.0	Black (BK)	450-20022
RMS 100-30	100	30.0	2.54	35 - 85	500.0	Black (BK)	450-20030
	100	30.0	2.54	35 - 85	1,000.0	Black (BK)	450-20031
RMS 139-38	139	38.0	2.77	45 - 120	1,000.0	Black (BK)	450-20041
RMS 185-55	185	55.0	2.74	65 - 160	1,000.0	Black (BK)	450-20050

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content.