


151152 DZH-16-200-PPV-A Flat cylinder - Series: All

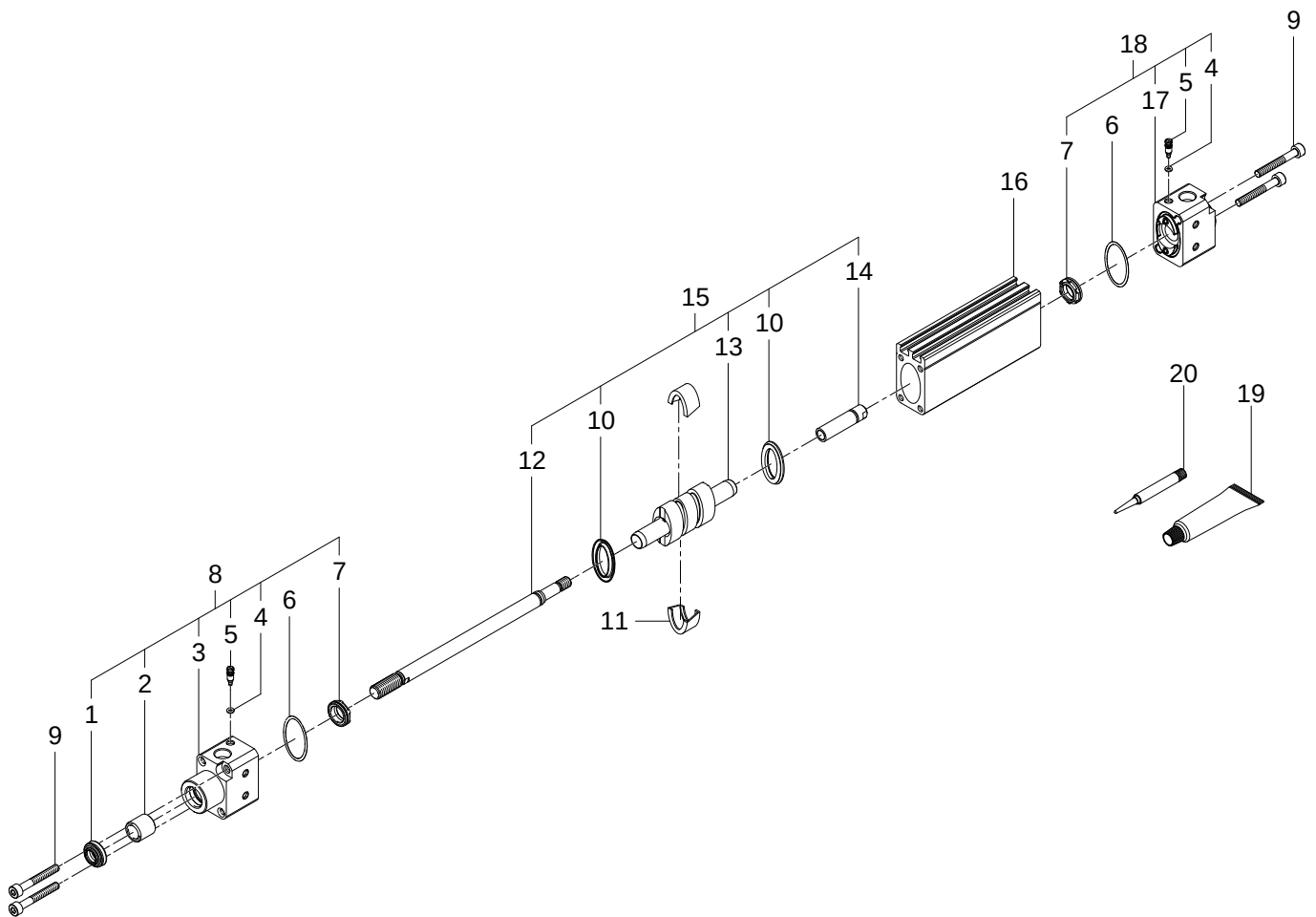

151152 DZH-16-200-PPV-A Flat cylinder - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	121125	DZH- 16- PPVA Set of wearing parts	Spare parts: 1, 6, 7, 10, 11	1	PC
1	248174	WIFC4-6X11,2X5,2-TPE-U Wiper seal	Grease using during assembly. See position 19	1	PC
2		SINT-C50 6X9X8 Cylinder bearing	Not available separately, see position 8	1	PC
3		DZH-16-PPV:CO Bearing cap	Not available separately, see position 8	1	PC
4		B-1X0,6-N-NBR70 O-ring ISO3601	Not available separately, see position 8+18 Grease using during assembly. See position 19	2	PC
5		DSNN- 16- PPV-A adjusting screw	Not available separately, see position 8+18	2	PC
6		17X1-N-NBR70 O-ring	Not available separately, see position A Grease using during assembly. See position 19	2	PC
7		DIFC1-8X11,6X3,5-TPE-U Buffer seal	Not available separately, see position 8+18+999 Grease using during assembly. See position 19	2	PC
8	118849	DZH-16-PPV Bearing cap module		1	PC
9	679713	ISO 4762-M4X20-10.9 Socket head screw	Use locking compound. See position 20 Tightening torque 3 Nm / 2.2 lbf ft	4	PC
10		LEFO1-21/12.2X2.45-TPE-U Lip seal	Not available separately, see position 15+999 Grease using during assembly. See position 19	2	PC
11		DZH-16 Guiding band	Not available separately, see position A Grease using during assembly. See position 19	2	PC
12		ARA-06-X0053,2-A1A6G Piston rod	Not available separately, see position 15	1	PC
13		DZH-16 Piston	Not available separately, see position 15	1	PC
14		ARA-06-X0053,2-A1A6G Piston rod	Not available separately, see position 15	1	PC
15	116271	DZH-16- -PPV-A Piston rod module	When ordering please specify the stroke (see type plate)	1	PC
16		DZH-16- Cylinder barrel	Not available Grease using during assembly. See position 19	1	PC
17		DZH-16-PPV:CO End cap	Not available separately, see position 18	1	PC
18	118850	DZH-16-PPV End cap module		1	PC
19	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
20	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC