

# Rittal – The System.

Faster – better – everywhere.

## LED system light – SZ 2500.320

Date : Jun 18, 2019

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# LED system light – SZ 2500.320

created: 18.06.2019 on [www.rittal.com/com-en](http://www.rittal.com/com-en)

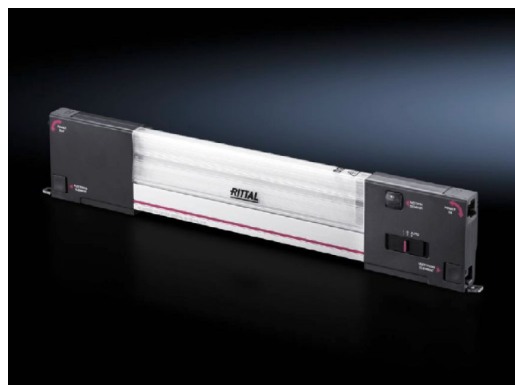

## Product description

<b>Description:</b>	LED system light – the first light especially for enclosures! Highly innovative LED technology for even more light into the very last corner.
<b>Benefits:</b>	Optimum illumination of the entire enclosure Optionally with clip, screw and magnetic attachment A configuration to suit every application
<b>Equipment:</b>	Motion sensor 90° rotating connector Adjustable light direction Adjustable light distribution
<b>Motion sensor:</b>	yes
<b>Material:</b>	Light body: Extruded aluminium Light cover: Polycarbonate (halogen-free) Light ends: PC-ABS (halogen-free)
<b>Colour:</b>	Enclosure: RAL 7016
<b>Protection category IP to IEC 60 529:</b>	IP 20
<b>Supply includes:</b>	Assembly screws

## Product features

<b>Dimensions:</b>	Width: 437 mm Height: 85 mm Depth: 37 mm
--------------------	------------------------------------------------

<b>Rated operating voltage:</b>	24 V - 56 V (DC)
<b>Operating temperature:</b>	Operation (environment): -20°C...+55°C
<b>Power consumption:</b>	13 W
<b>Luminous flux:</b>	1200 lm
<b>Light colour:</b>	4000 K (neutral white)
<b>Protection category:</b>	III (SELV)
<b>Connection options:</b>	Infeed, 2-pole Through-wiring, 2-pole
<b>Light – installation type:</b>	Screw-fastening Clip attachment Magnetic attachment (accessory)
<b>Packs of:</b>	1 pc(s).
<b>Weight/pack:</b>	0.65 kg
<b>Copper weight (kg per piece):</b>	0
<b>EAN:</b>	4028177918818
<b>Customs tariff number:</b>	94054099
<b>ETIM 6.0:</b>	EC000321
<b>ETIM 5.0:</b>	EC000321
<b>eCl@ss 8.0/8.1:</b>	27189241
<b>eCl@ss 7.0/7.1:</b>	27189241
<b>eCl@ss 6.0/6.1:</b>	27189241
<b>eCl@ss 5.1/5.1.4:</b>	27189241
<b>Product description:</b>	SZ System Light LED, 1200 Lumen, L: 437 mm, 24 V DC, with integral motion sensor

## Approvals

<b>Approvals:</b>	CCC UL + C-UL
-------------------	------------------

---

**Certificates:**

EAC

---

**Declarations:**

Declaration of conformity

---