


COMBINATION SPANNER ANTI SLIP METRIC 12MM

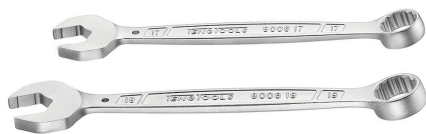

- Anti slip metric combination spanner
- Off set at 15° for easier use on flat surfaces
- TengTools hip grip design on the ring and open end for contact with the flat side of the fastening
- TengTools anti slip design on the open end to give a much better grip with less risk of damaging the fastening

Anti Slip Combination Spanner 12mm

General information

Country of origin: Taiwan
Barcode: 5020385044111
Tariff code Europe: 8204110000
ECCN US: EAR99
ETIM: EC002176
UNSPSC: 271111713

Dimensions

Net weight (g): 58
Length: 160 mm

Attributes

Product type: Combination Spanners
Material: CrV
Certificates: N/A
Size: 12 mm
Tethering facility: Yes
Spanner type: Anti slip
Unit of measurement: Metric
Jaw diameter: 27.2
Jaw height (mm): 5.5
Offset angle jaw (°): 15
Ring diameter (mm): 18.0
Ring height (mm): 8.5
Offset angle ring (°): 15

Features

mm

Technical changes and errors may occur. 01-08-2024 19:54



DESIGNED IN SWEDEN

TengTools is a Swedish company present in more than 30 markets worldwide, and offers hand tools in smart storage solutions for demanding professionals within the automotive, maintenance and engineering sectors, as well as motor sport enthusiasts who aspire to use the same tools as top mechanics across the globe.



Sandbergsvägen 3
 441 39 Alingsås, Sweden