

405.8MT | MICRO-TECH® "SMALL MESH" CUTTERS: THIN




Norm :

NF ISO 9654, ISO 9654, DIN ISO 9654, ASME B107.500

Description :

- These small mesh pliers are ideal for small electronic components.

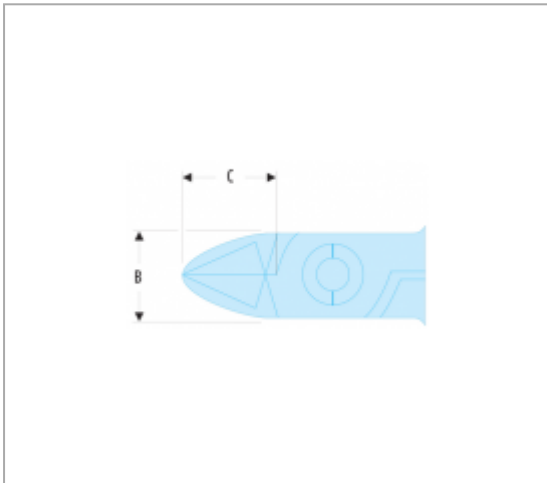

Informations :

	405.8MT
B [mm]	8,5
C [mm]	9
E [mm]	6
L [mm]	110
Cut	h
Cu - Ni Ø [mm]	0,2 - 1
Bits	212.E10
Fe 30 HRc diam. [mm]	0,5

	405.8MT
Piano Diameter [mm]	-
[g]	60