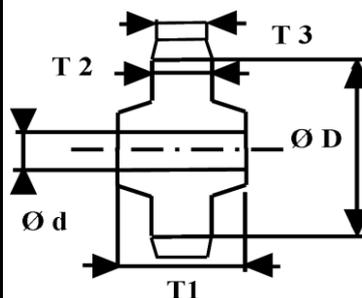


Solid black standard Rubber Trolley Wheel 300mm Hub 25, 250kg

Standard Rubber-tyred wheel

PRODUCT

Article number 7423062500

Product Details

Wheel Rim : riveted steel plates. Bright zinc-plated protection.

Tyre : solid, black standard rubber.

Hub : symmetrical, with roller bearing.

Specifications

Wheel Diameter - ØD ± 1%	300 mm
Hub Type	Roller bearing
Hub Length T1	60 mm ±1
Width of Tread T2	50 mm ±1
Width of Tread-on floor T3	38 mm ±1
Axle Hole Ø d	Ø 25 mm
Hardness of tread A ±4	A 82 Shore
Load capacity	250 Kg
Temperature	-20 / +60 °C
Weight	3,30 Kg

TECHNICAL DATA

Applications :

Quiet materials handling with horizontal effort.

Resistance to tyre shedding and side impact.

Lightweight.

Suitable for trolleys on industrial floors (factory, warehouse, sack truck, ...)