

Metalux 7

EUROPEAN PROFILE INTERAXIS 70 AND 85 MM MORTISE LOCK




The Metalux n°7 is a European profile single point mortise lock for metal doors. Designed for an integration into aluminium and steel profiles, it adapts perfectly to a new or replacement environment. Its interaxis is 70 or 85 mm. Reversible, it is equipped with a deadbolt and a silent latch which ensures a soft entry into the strike plate. The anti-corrosion treatment of its interior parts ensures durability over time.



TECHNICAL FEATURES

Locking elements	Deadbolt and latch
Key action on latch	Yes
Reversible	Yes
Interaxis	70 or 85 mm
Backset	21, 24.5 or 31 mm
Case depth	36, 39.5 or 46 mm (Depths 21 and 28 mm also available within the references 7/21-7/28)
Follower	8 mm
Recommended cylinder	European cylinder with DIN cam
Supplied accessories	Strike plate

TECHDRAWING

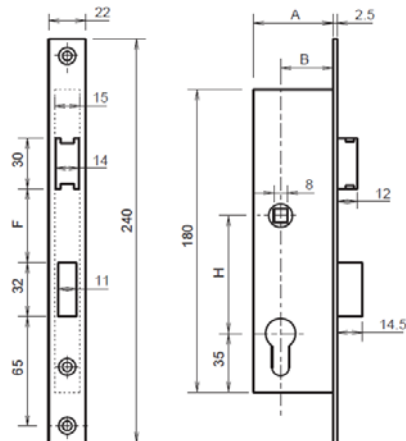

Cotes variables sous têtère		
A	36	39.5 46
B	21	24.5 31
HF	70-45.5 85-62.5	