

USB-C flush-mounted charger T65.02 Comfort with Power Delivery (PD)

Item-no.: 6560x0200 | 6560x0201



USB-C flush-mounted insert with cover (white, 55x55mm) for installation into standard flush-mounted boxes Ø 65mm with device screws (!), installation according to DIN 49073 (optional with frame colour white)

Compatible with 55x55 switch range programmes (inner dimensions of frame 55x55mm) white, similar to RAL9010 (e.g. Busch Balance SI by Busch-Jaeger or Standard 55 by GIRA, etc.)

18-Watt power supply with power delivery (PD) fast charging, for fast and safe charging of laptops, tablets, smartphones, wearables and further small electronic devices with USB-C port

Variable power adjustment: up to 18W

Supports different charging protocols e.g. QC2.0/QC3.0, FCP, AFC, BC1.2, APPLE

Screw terminal to connect wires of the house installation, up to 2,5mm² max. (2xL/2xN – for easy looping in multiframes)

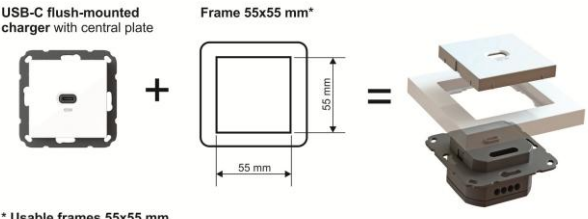









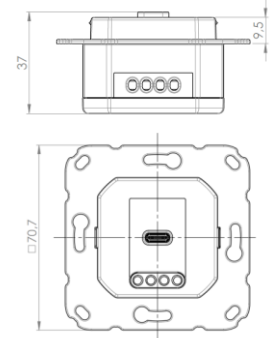

EHMANN advantage - 100% quality control, 5 years warranty

EHMANN quality – High-grade manufacturing and reliable function



USB-C flush-mounted charger T65.02 Comfort with Power Delivery (PD)

Technical data

<p>Power: max. 18 W 1x USB-C Output</p>	<p>110 - 230V / 50-60 Hz Input Voltage</p>	<p>5 - 12V Output Voltage</p>																																						
 <p>USB-C flush-mounted charger with central plate</p> <p>Frame 55x55 mm*</p> <p>* Usable frames 55x55 mm</p> <table border="0"> <tr> <td>GIRA</td> <td>pure white</td> <td>Standard 55, E2, E22, Event, Esprit</td> </tr> <tr> <td>BUSCH JAEGER</td> <td>alpine white</td> <td>Busch balance S1</td> </tr> <tr> <td>JUNG</td> <td>alpine white</td> <td>A 500, A PLUS, A CREATION, AS 500, A550, A FLOW</td> </tr> <tr> <td>BERKER</td> <td>polar white</td> <td>S1, B3, B7</td> </tr> <tr> <td>MERTEN</td> <td>polar white</td> <td>1M, M-Smart, M-Plan, M-Pure</td> </tr> </table> <p>All listed white shades are similar to RAL9010</p>	GIRA	pure white	Standard 55, E2, E22, Event, Esprit	BUSCH JAEGER	alpine white	Busch balance S1	JUNG	alpine white	A 500, A PLUS, A CREATION, AS 500, A550, A FLOW	BERKER	polar white	S1, B3, B7	MERTEN	polar white	1M, M-Smart, M-Plan, M-Pure	<table border="1"> <thead> <tr> <th></th> <th>Professional</th> <th>Kombi</th> <th>Comfort</th> </tr> </thead> <tbody> <tr> <td> <ul style="list-style-type: none"> ● = Fast charging ● = Slow charging ✘ = No charging / use at the same time </td> <td>  </td> <td>  </td> <td>  </td> </tr> <tr> <td>5W</td> <td>✓</td> <td>✓</td> <td>✓</td> </tr> <tr> <td>15W (max. 25W)</td> <td>✓</td> <td>✓</td> <td>✓</td> </tr> <tr> <td>18W (max. 30W)</td> <td>✓</td> <td>✓</td> <td>✓</td> </tr> <tr> <td>65W (max. 100W)</td> <td>✓</td> <td>●</td> <td>✘</td> </tr> </tbody> </table>		Professional	Kombi	Comfort	<ul style="list-style-type: none"> ● = Fast charging ● = Slow charging ✘ = No charging / use at the same time 				5W	✓	✓	✓	15W (max. 25W)	✓	✓	✓	18W (max. 30W)	✓	✓	✓	65W (max. 100W)	✓	●	✘
GIRA	pure white	Standard 55, E2, E22, Event, Esprit																																						
BUSCH JAEGER	alpine white	Busch balance S1																																						
JUNG	alpine white	A 500, A PLUS, A CREATION, AS 500, A550, A FLOW																																						
BERKER	polar white	S1, B3, B7																																						
MERTEN	polar white	1M, M-Smart, M-Plan, M-Pure																																						
	Professional	Kombi	Comfort																																					
<ul style="list-style-type: none"> ● = Fast charging ● = Slow charging ✘ = No charging / use at the same time 																																								
5W	✓	✓	✓																																					
15W (max. 25W)	✓	✓	✓																																					
18W (max. 30W)	✓	✓	✓																																					
65W (max. 100W)	✓	●	✘																																					
<p>Supported protocols:</p> <p>QC2.0/QC3.0, FCP 5V/9V/12V, AFC 9V, BC1.2 5V/1.5A, APPLE 5V/2.4A PD</p>																																								
<p>Connection: screw terminals up to 2,5 mm² (rigid)</p> <p>Power consumption/Stand-by: < 0,08W</p> <p>Short circuit/overload protection: electronic</p> <p>In order to guarantee maximum charging power, please pay attention to using original / PD charging cables.</p>																																								
<p>Before installing and using the device, please read the instruction manual carefully.</p>		<table border="0"> <tr> <td>Item-no. 6560x0200</td> <td>EAN 4012096011521</td> <td>PU 10 Weight: net 100g</td> <td rowspan="2">without frame 71 x 71 x 37 mm Dimension (L x W x H)</td> </tr> <tr> <td>Item-no. 6560x0201</td> <td>EAN 4012096026167</td> <td>PU 10 Weight: net 120g</td> <td>with frame 82 x 82 x 37 mm Abmessung (L x B x H)</td> </tr> </table>	Item-no. 6560x0200	EAN 4012096011521	PU 10 Weight: net 100g	without frame 71 x 71 x 37 mm Dimension (L x W x H)	Item-no. 6560x0201	EAN 4012096026167	PU 10 Weight: net 120g	with frame 82 x 82 x 37 mm Abmessung (L x B x H)																														
Item-no. 6560x0200	EAN 4012096011521	PU 10 Weight: net 100g	without frame 71 x 71 x 37 mm Dimension (L x W x H)																																					
Item-no. 6560x0201	EAN 4012096026167	PU 10 Weight: net 120g		with frame 82 x 82 x 37 mm Abmessung (L x B x H)																																				