


Cover plate
VABB-P19-16-T
Part number: 8154656

FESTO

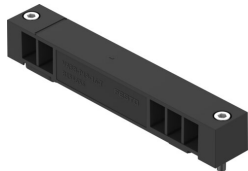

 [General operating condition](#)

Data sheet

Feature	Value
Size	16
Grid dimension	16 mm
Sealing principle	Soft
Operating pressure	-0.1 MPa ... 0.7 MPa
Operating pressure	-1 bar ... 7 bar
Suitability for vacuum	Yes
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 70 °C
Media temperature	5 °C ... 50 °C
Degree of protection	IP65
Ambient temperature	5 °C ... 50 °C
Nominal torque	0.75 Nm
Product weight	14.9 g
Electrical connection	Plug-in
Type of mounting	Via through-hole and screw
Note on materials	RoHS compliant
Material seals	EPDM
Material housing	PA66-GF30