



Datasheet

ENGLISH

RS Unshielded Test Lead Wire 2.5 mm² CSA 500 V Red Silicone Rubber Single Core, 462 Strands 5m

RS Stock number 748-1995



Product Code: Silicone test lead wire 2.5mm²

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Single

Cable Construction

Conductor	Tinned Copper
Cross section	2.5mm ²
Construction(±0.003mm)	T0.08× 462
Standard Dia.	1.98
Jacket	silicone rubber
Thickness	0.95
Jacket Dia.(mm)	3.90±0.15
Color	Red: Black; Blue; Yellow Green


Marking

No Printing

PACKAGING

5M/ plastic Bag

Suitable pieces/Box

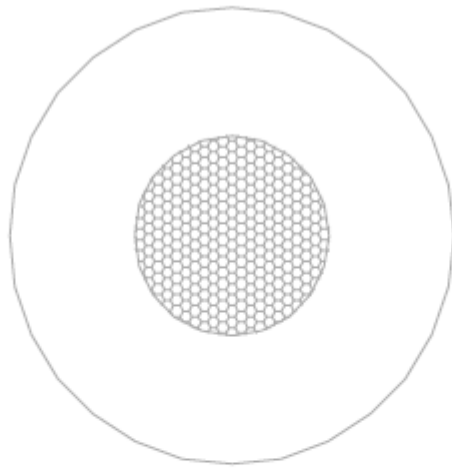

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	8.02
Min.Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-55~+200
Rated Voltage (V)	300/500