

Signal lamp with integrated filament lamp, 10 mm, square bezel, 28 Volt, bezel red, Flat quick-connect terminal 2.8 x 0.8 tin-plated



fields of application

- Measurement-control-regulation
- Electrical engineering
- Mechanical and system engineering
- Signalling systems
- Model construction

special features

- Three shapes: round, square or arrow-shaped
- Integrated luminous element
- Filament lamp, 28 V, color: yellow
- Neon lamp, 230 V, color: red
- Luminous element neon lamp, 230 V, color: green or blue



description

Signal lamps with integrated filament lamp, neon lamp or luminous element neon lamp, mounting hole diameter 10 mm

technical data

➤ general

Bezel color	red
Property of bezel / mushroom	transparent
Bezel shape	square
illuminated	Yes
Packaging unit	10 pcs.
net weight	2.4 g
Degree of protection, front side, according to DIN EN 60529	IP40
MOQ order	50 pcs.
RoHS compliant	Yes
REACH compliant	Yes

direct links

- [RAFI eCatalog](#)

➤ mounting diameters

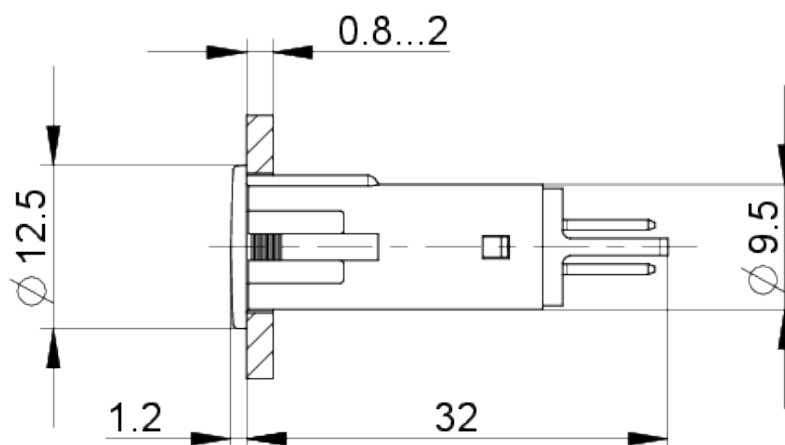
Mounting hole	10 mm
Mounting depth	30 mm
Installation height	3 mm

➤ mechanical data

Fixing	Pushing into mounting hole
Solderability	Yes
Terminal on the rear	Flat quick-connect terminal 2.8 x 0.8 tin-plated

➤ electrical data

Operating voltage of the luminous element, max.	28 V
---	------

drawings**Dimensioned drawing****Mounting hole drawing**