



CoreLine Downlight

DN125B LED10S/840 PSR WH

DN125B - LED Module, system flux 1000 lm - Power supply unit regulating

Whether for a new building or renovation of an existing space, customers want lighting solutions that provide quality of light and substantial energy and maintenance savings. Part of Philips' high-quality CoreLine LED family, the new CoreLine Downlight range of LED products can be used to replace conventional CFL downlights in general lighting applications.

Product data

• General information

Product family code	DN125B [DN125B]
Number of light sources	1 [1 pc]
Lamp family code	LED10S [LED Module, system flux 1000 lm]
Lamp colour code	840 [840 white]
Light source replaceable	No [No]
Driver/power unit/transformer	PSR [Power supply unit regulating]
Driver included	Yes [Yes]
Optical cover/lens type	No [-]
Dimmable	Yes [Yes]
Connection	SCREW [Screw connector]
Protection class IEC	CL I [Safety class I]
Ingress protection code	IP20 [Finger-protected]
Mech. impact protection code	IK02 [0.2 J standard]
Diameter	D150 [150 mm]
Colour	WH [White]
Standard RAL colour	RAL9010 [Pure white]
Glow-wire test	650/5 [Temperature 650 °C, duration 5 s]
Flammability mark	F [For mounting on normally flammable surfaces]
CE mark	CE [CE mark]
ENEC mark	No [-]

• Electrical

Input voltage	220-240 V [220 to 240 V]
Input frequency	50-60 Hz [50 to 60 Hz]

• Mechanical

Housing material	ALU [Aluminium]
Reflector material	ALU [Aluminium]

• Initial perform. (IEC compliant)

Initial input power	13 W [13 W]
Initial luminous flux	1000 Lm
Initial LED luminaire efficacy	80 Lm/W
Lamp colour temperature	4000 [4000 K]
Colour Rendering Index	>80 [>80]
Initial chromaticity	(0.38, 0.38) SDCM <5

• Over time perform. (IEC compliant)

Median useful life	50000 hr
L80B50	
Driver failure rate at 5000 h	1.5 %

• Application conditions

Average ambient temperature	T25 [+25 °C]
Ambient temperature range	+10 to +40°C [+10 to +40 °C]
Maximum dim level	1%-ELV [1% (depends on dimmer, ELV)]
Suitable for random switching	Yes [Yes (relates to presence/movement detection and daylight harvesting)]

PHILIPS

CoreLine Downlight


• Product Data

Order code 294889 99
Full product code 871016329488999
Full product name DN125B LED10S/840 PSR WH
Order product name DN125B LED10S/840 PSR WH
Pieces per pack 1
Packs per outerbox 12
Bar code on pack - EAN1 8710163294889


Bar code on outerbox - EAN3 8710163294926
Logistic code(s) - 12NC 911401799101
Net weight per piece 0.370 kg



Dimensional drawing

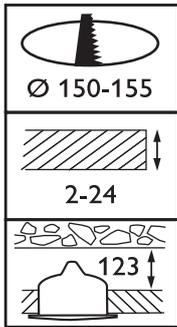

DN125B LED10S/840 PSR WH

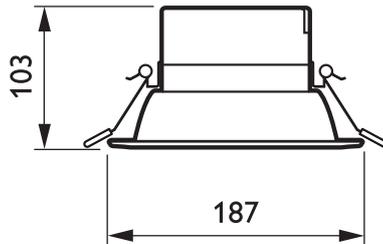

© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, August 5
data subject to change