


Technical data

RNA22/8LL/3AS

Roller follower without inner ring



VISUAL (S)

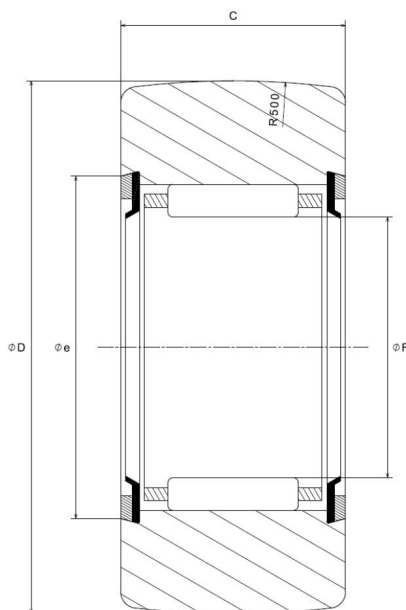

PRODUCT DEFINITION

Brand	NTN
D - External diameter	24 mm
Fw - Under rollers diameter	12 mm
C - Width of bearing, drawn cup or outer ring	11,8 mm
e - Inlet diameter of roller or washer	18 mm
R - Track roller radius	500 mm
Bearing with/without cage	Avec
Precision class	P0
Mass	0,027 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

RNA22/8LL/3AS

Roller follower without inner ring

PRODUCT PERFORMANCE

Cr - Dynamic load rating	5,15 kN
C0r - Static load rating	5,25 kN
Track load capacity spherical outer ring	1,9 kN
N lim - Grease lubrication limit speed	10000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	RNA22/8LL/3AS
Image	NRBRNA22_LL_1.jpg, NRBRNA22_LL_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15