

SIVACON, Roof, with Ventilation openings with Ventilation openings IP20, W: 800 mm, T: 1000 mm, zinc-plated

Model			
product brand name		SIVACON	
product designation		top plate	
design of the product		With ventilation openings	
design of the surface		zinc plated	
design of the product EMC version		No	
Protection class			
protection class IP		IP20	
Suitability			
suitability for use for outside use		No	
Product details			
product component			
• cable entry		No	
• ventilation		Yes	
Mechanical Design			
width		800 mm	
depth		1 000 mm	
ventilation cross section outlet can be used		3 254 cm²	
net weight		9.6 kg	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
Miscellaneous	 Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875 Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1080-2UD20-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1080-2UD20-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1080-2UD20-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

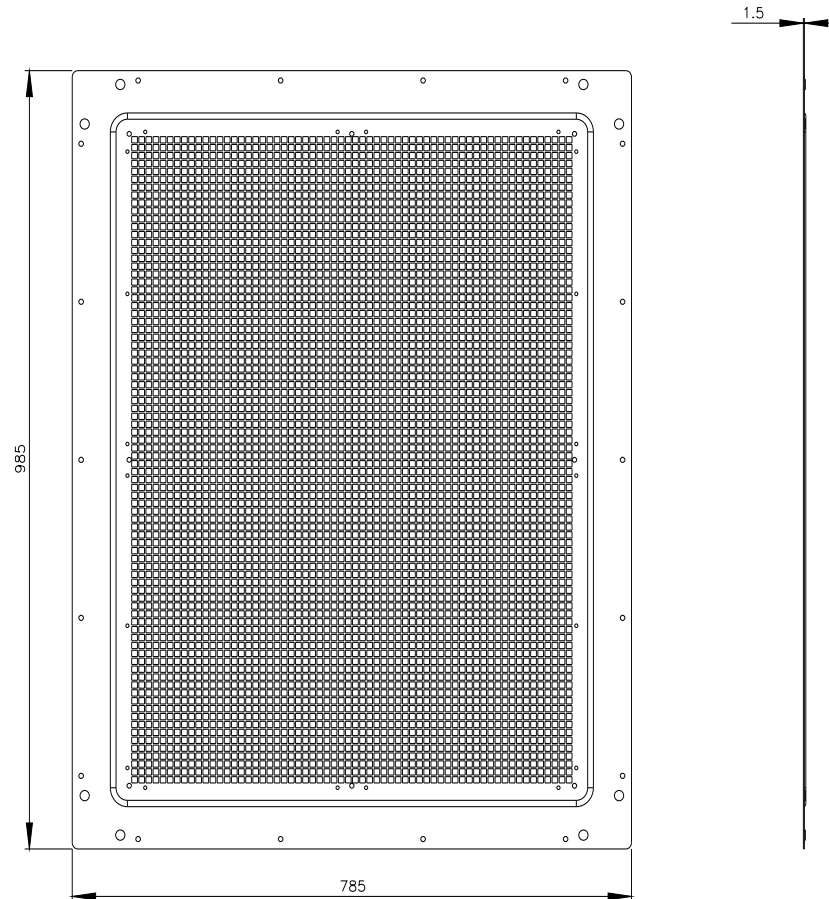

last modified:

1/16/2025 

