


Axial kit EAMM-A-T42-40P

Part number: 8217184

FESTO

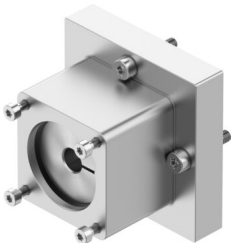

Data sheet

 [General operating condition](#)

Feature	Value
Nominal length	43 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm ²
Transmittable torque	7.5 Nm
Product weight	178 g
Interface code, actuator	T42
Interface code, motor in	40P
Note on materials	RoHS compliant