


DX06WR012N Datasheet

 [View Product Page](#)

Product Name // DX06WR012N, 6mm Diameter, Wire Leads 200mm, Red, 12V, Nickel Plated Brass

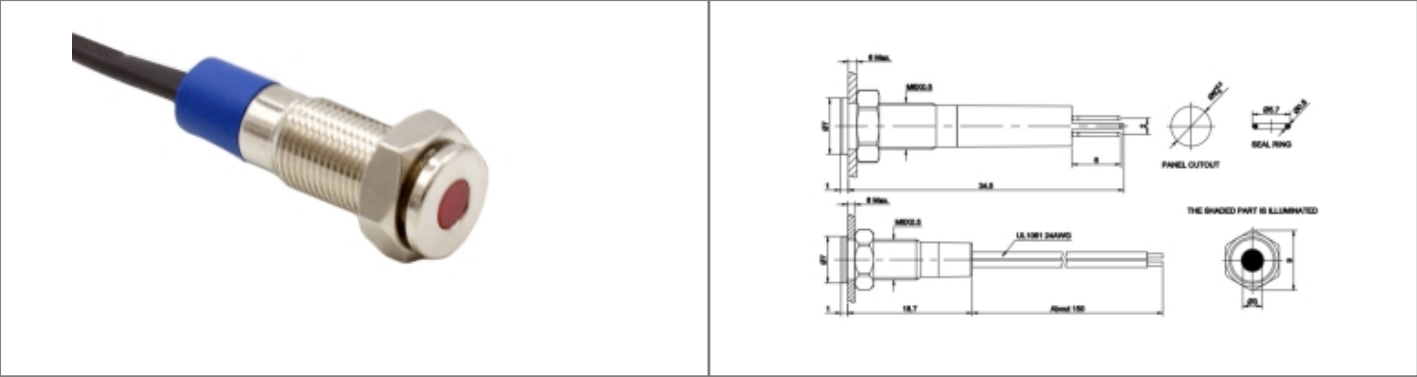

// **Product Description:**

- | | |
|--|---|
|  DX Series |  Red |
|  6mm Diameter |  12V |
|  Wire Leads 200mm |  Nickel Plated Brass |

// **General Information:**

Product Display Title:	6mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	6mm Vandal Resistant Indicator DX Range
Bezel Finish:	Polished
Body Colour:	Nickel
Body Material:	Brass
Body Material Type:	Metal
Diameter:	6mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Red
Illumination Voltage:	12V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Polished
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	6mm Diameter circle
Rohs Compliant:	Yes
Thread Size:	M6 X 0.5

// **Product PDF Links**

 [6mm & 8mm Vandal Resistant...](#)

// **Product 3D CAD Model Links**

 [DX06WR012N3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)