

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



Valve connectors, 3-position, Valve connector C (8 mm), Screw connection, cable gland Pg9, external cable diameter 6 mm ... 8 mm

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Commercial Data

Item number	1527951
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	BF2DDA
Product Key	BF2DDA
Catalog Page	Page 79 (PC-2005)
GTIN	4017918981037
Weight per Piece (including packing)	12.09 g
Weight per Piece (excluding packing)	11.93 g
Customs tariff number	85366990
Country of origin	HU

Technical Data

Notes

Assembly instruction:

NOTE: Observe the permissible bending radii when laying conductors, since the degree of protection may be put in jeopardy if the bending forces are too high. Alleviate mechanical loads upstream of the connector, e.g. by using cable ties.

Product properties

Product type	Valve connector
Number of positions	3
No. of cable outlets	1
Shielded	no
Pg screw connection	Pg9

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Electrical properties

Contact resistance	$\leq 15 \text{ m}\Omega$
Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage U_N	250 V AC 250 V DC
Nominal current I_N	6 A
Protective circuit	unwired

LED signaling

Status display	No
Status display present	No

Connector

Insertion/withdrawal cycles	50 (Valve connector)
-----------------------------	----------------------

Header 1

Head design	Valve connector C (8 mm)
Number of positions	3
Insertion/withdrawal cycles	50 (Valve connector)
Connection method	Screw connection
Number of positions	3
Insertion/withdrawal cycles	50 (Valve connector)
Connection method	Screw connection

Dimensions

External dimensions

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Outside diameter	6 mm ... 8 mm
------------------	---------------

Material specifications

Flammability rating according to UL 94	HB
Sealing material	NBR
Material housing valve plug	PA6
Contact material	CuZn
Valve plug contact insert material	PA6
Contact surface material	Ni


Environmental and real-life conditions

Ambient conditions


Degree of protection	IP65
Ambient temperature (operation)	-30 °C ... 100 °C (valve plug)

Drawings

Circuit diagram

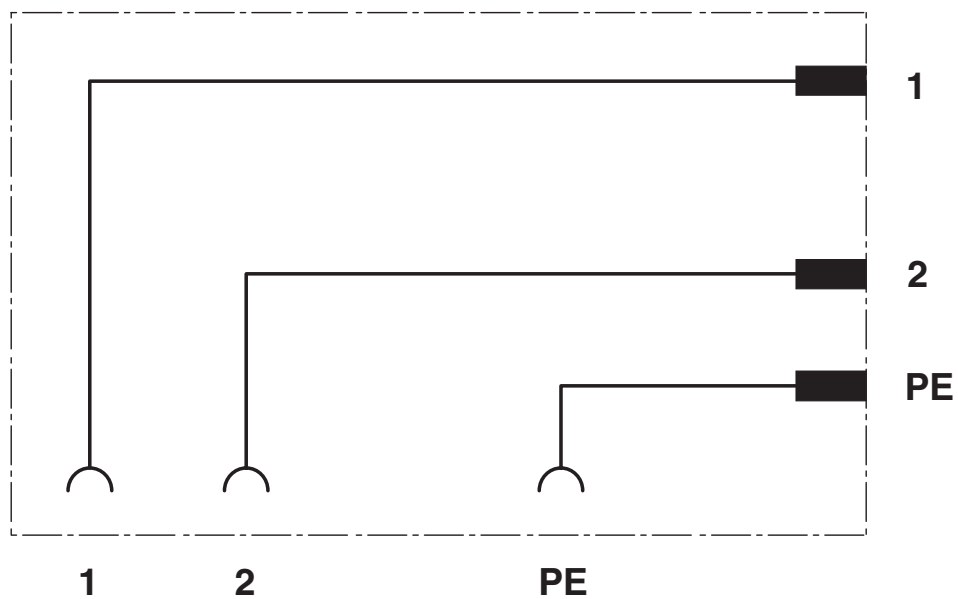

Dimensional drawing

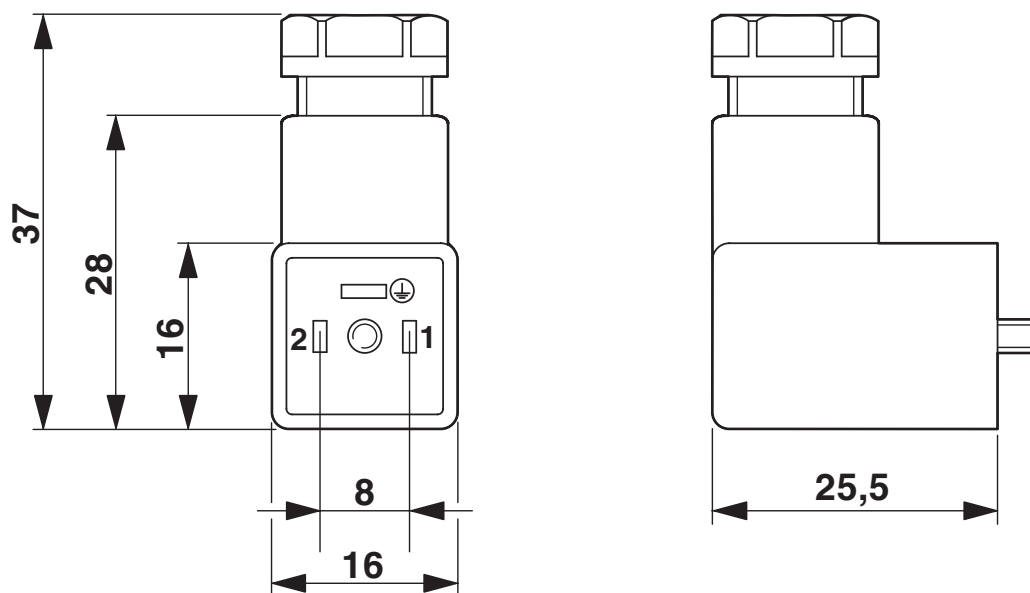

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Approvals



EAC

Approval ID: RU C-DE.BL08.B.00511

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Classifications

ECLASS

ECLASS-9.0	27440105
ECLASS-10.0.1	27440105
ECLASS-11.0	27440105

ETIM

ETIM 8.0	EC003623
----------	----------

UNSPSC

UNSPSC 21.0	31251500
-------------	----------

Valve connectors - SACC-V-3CON-PG7/C



1527951

<https://www.phoenixcontact.com/gb/products/1527951>

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

Phoenix Contact 2022 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk