


DYMO®

Rhino™ 6000

Industrial Labelling Tool

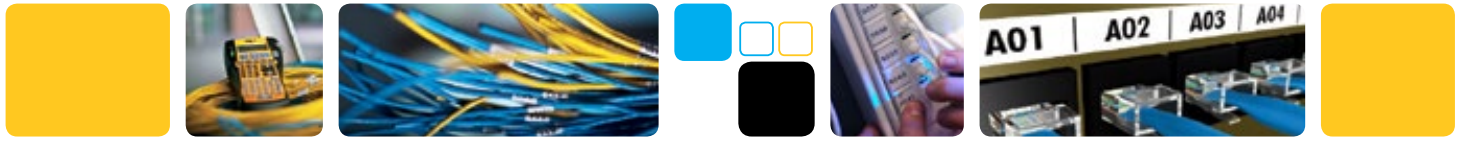

Introducing the labelling tool that gets it done fast

The Rhino 6000 is an ideal labelling tool for datacom, professional Audio/Video, security and electrical systems, as well as all types of labelling throughout commercial buildings, factories, warehouses, and even homes.

The Rhino 6000 Label Printer is the first printer in the Rhino product family to offer PC connectivity. The installer can either create labels before reaching the worksite by downloading files from any Windows-based software program or they can create or edit labels when they reach the worksite.

Rhino 6000 Features:

- 1 Intuitive Graphical Interface** - Create, edit and preview multiple labels on the large backlit LCD
- 2 One-Touch, Power-Assisted Cutter** - Eliminate the fatigue of manual cutting and increase efficiency
- 3 Hot Keys** - Eliminate guesswork, complicated menus and enjoy fast and easy formatting of commonly-used label types
- 4 Symbols** - Over 100 pre-programmed industry symbols
- 5 Save Your Labels** - Customise over 1,000 labels with logos and symbols and recall them instantly
- 6 Quick-Charge Li-Ion** - Rechargeable Battery with on-screen battery life indicator
- 7 Library** - Over 150 pre-programmed industry terms and the ability to customise your own library of terms
- 8 Powerful Serialisation** - Built-in wizards for simple and advanced serialisation
- 9 Integrated Impact Bumpers** - Protects against harsh conditions while allowing easy access to label cartridge



PC Connectivity

 
Works best with RHINO CONNECT™ Software* to:

- Upload/download label files for in-the-field and on-demand printing.
- Insert customised graphics, logos, symbols and industry terms.
- Import data from any Windows® based program.
- Create labels using the integrated step-by-step wizard.
- Print labels directly from RHINO CONNECT™ Software.

Download templates from leading manufacturers with exact label spacing for Patch Panels, 110 and Terminal blocks.

Visit www.dymo.com/en-US

***Software only included in the Hard Case Kit**

IND LABEL APPLICATIONS		LABEL COLOUR	6mm	9mm	12mm	19mm	24 mm
Labels that stick and stay stuck. DYMO Industrial labels are tough– jobsite tested and UL recognised. Labels won't smear or fade and are built with industrial-strength adhesives to resist moisture, UV light and extreme temperatures. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO Industrial labels have you covered. DYMO Industrial labels are designed to work with Rhino and LabelManager printers and to perform on a variety of surfaces. LEARN MORE: www.dymo.com.au		BLACK ON WHITE	–	SD18443	SD18444	SD18445	–
		WHITE ON BLACK	–	1805437	1805435	1805436	1805432
VINYL Length 5.5m - UL Recognised Component to UL969 - RoHS compliant  							
PERMANENT POLYESTER Length 5.5m - UL Recognised Component to UL969 - RoHS compliant  		BLACK ON WHITE	1805442	SD18482	SD18483	SD18484	SD1734523
		BLACK ON CLEAR	1805440	18508DMO	622289	622290	1805433
		BLACK ON METALLIC	–	18485	18486	18487	1805434
HEAT SHRINK TUBE Length 1.5m - UL Recognised Component to UL224 - Meets MIL-STD-202G, MIL-M-81531 & SAE-DTL 23053/5 (Class 1 & 3) - RoHS compliant  		BLACK ON WHITE	SD18051	SD18053	SD18055	SD18057	–
		BLACK ON YELLOW	18052	18054	18056	18058	–
FLEXIBLE NYLON Length 3.5m - UL Recognised Component to UL969 - RoHS compliant  		BLACK ON WHITE	–	–	SD18488	SD18489	SD1734524
		BLACK ON YELLOW	–	–	SD18490	SD18491	SD1734525
SELF-LAMINATING Length 5.5m - RoHS compliant  		BLACK ON WHITE	–	–	–	–	SD1734821

RHINO 6000

Code: SD773820
Barcode: 5411313001748

Box includes:

- Rhino 6000 printer
- 24 mm black on white vinyl tape
- Quick Reference Guide
- Rechargeable lithium-ion battery pack
- AC adaptor
- Registration card

Product specifications:

- Quick-charge lithium-ion rechargeable battery and on-screen battery life indicator
- 1 year limited warranty
- Unit weight: 1.18kg
- Units per master carton: 3
- Master carton dimensions (L x W x H): 304 x 304 x 279mm
- Master carton weight: 6.35kg

RHINO 6000 HARD CASE KIT

Part No. SD771980
Barcode: 5411313226813

Hard case kit includes:

- Rhino 6000 printer
- Rhino CONNECT™ software
- Durable hard carry case
- 24 mm black on white vinyl tape
- 9 mm black on white vinyl label cartridge
- Quick Reference Guide
- Rechargeable lithium-ion battery pack
- AC adaptor
- USB cable

Product specifications:

- Quick-charge lithium-ion rechargeable battery and on-screen battery life indicator
- 1 year limited warranty
- Unit weight: 2.2kg
- Units per master carton: 3
- Master carton dimensions (L x W x H): 482 x 360 x 330mm
- Master carton weight: 8.16kg

DYMO, the DYMO logo and Rhino are trademarks or registered trademarks of Newell Rubbermaid. All other trademarks are the property of their respective owners.

Distributed by:
Newell Australia Pty Ltd
www.dymo.com.au



Newell Rubbermaid
Brands That Matter