



Brand of NTN corporation


Technical data

BBER30LUU

Flange type ball bushings



VISUAL (S)

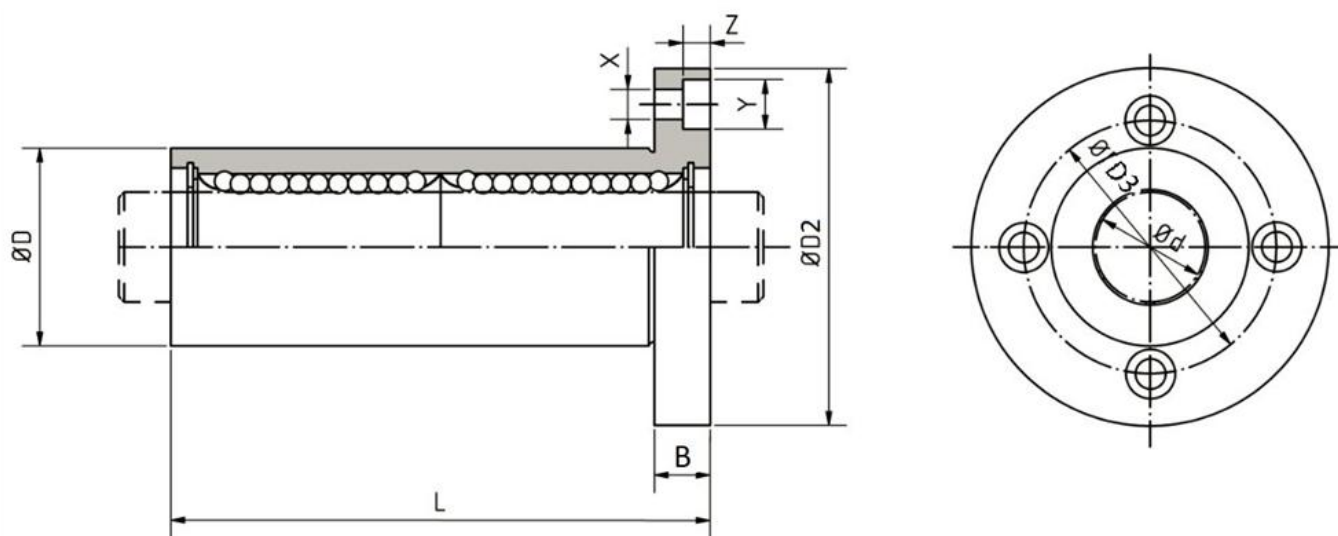

PRODUCT DEFINITION

Brand	SNR
Design type	BBER
Ball bushings category	Flange type ball bushings
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	30 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter tolerance	0,013/-0,002
D - External diameter	47 mm
D - External diameter tolerance	0/-0,019
L - Length	123 mm
L - Length tolerance	0,3/-0,3
B - Flange width	10 mm
D2 - Diameter	76 mm
D3 - Diameter	62 mm
X	6,6 mm
Y	11 mm
Z	6,1 mm
Maximum eccentricity	0,017 mm
Number of ball rows	6
Mass	0,815 kg

PRODUCT PERFORMANCE

Cmin	2,6 kN
Cmax	3,328 kN
C0min	5,49 kN
C0max	7,027 kN
Permissible static Moment My	78 N/m
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

BBER30LUU

Flange type ball bushings

ESHOPDONOTDISPLAY

Reference	BBER30LUU
Image	BBER-L_1.JPG, BBER-L_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15