


Item no.: 770-125
 Product description: socket with relief housing 5 pole pin spacing 10 mm / 0.394 in
 100% protected against mismatching wire diameter 9-13 mm

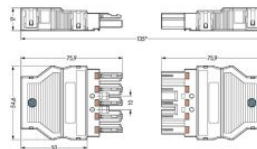

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	20 (WINSTA)
pole count	5
Cross section [mm ²]	0.5 - 4 mm ²
Cross section [AWG]	20 - 12 AWG
Connection method	CAGE CLAMP®S Connection
Measured voltage EN	400 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	25 A
Weight	28.23 g
Color	white
No. of connection Points	10
No. of potentials	5
Height	17 mm
Height	0.669 in
Width	54.6 mm
Width	2.15 in
Depth	75.9 mm
Depth	2.988 in

Strip length from
Strip length to
Strip length

9 mm
9 mm
0.35 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
770-125	ABS	06-HG154986/11-PDA	400	25	0,5-4,0
770-125	CBCertificateVDE	DE1-29543	250/400	25	0,5-4
770-125	CCA		400	25	0,5-4,0
770-125	cURus	E45171	600	20	12
770-125	DNV	E-9217	400	25	4
770-125	GL	42875-02HH	400	25	4
770-125	KEMA		400	25	0,5-4,0
770-125	LR	02/20050(E3)	250	25	2,5
770-125	PRS	TE/1719/880590/08	400	25	0,5-4,0
770-125	PSE	JET0695-43009-1002	600	20	12
770-125	VDE	Ausweis.Nr.30726	250/400	16/25	0,5-4,0

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected