




LED Spot PAR38 E27 DIM 15W (120W) 1150lm 830 40° IP65

Article number: 145516

BAI BaiSpot LED PAR38 E27 15W (120W) 1150lm 3000K 40° Dimmable 230V-240V 121x132mm Only the cover is IP65 LED-lamp

The so-called LED spots from the BaiSpot series are characterized by a much longer lifespan and significantly less energy consumption than their halogen predecessors. Due to the compact design, they are easily interchangeable. Spots are mainly used to provide directed light from the ceiling or wall. This version of the BaiSpot is dimmable. Use the correct LED dimmer. IP65 front disc: suitable for outdoor use if the lamp base is protected against contact with water. Ambient temperature range: -20°C to +45°C.

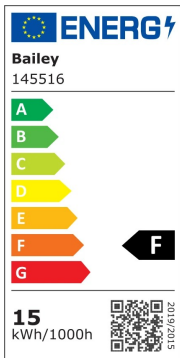

General ETIM properties

| | |
|---------------|--|
| ETIM group | Lamps |
| ETIM class | LED-lamp/Multi-LED |
| Name | LED Spot PAR38 E27 DIM 15W (120W) 1150lm 830 40° IP65 |
| Brand | Bailey |
| Productseries | BaiSpot LED MV |
| Producttype | PAR38 |

ETIM specifications

| | |
|---|---------------------|
| Socket | E27 |
| Luminous flux [lm] | 1150 - 1150 |
| Nominal voltage [V] | 220 - 240 |
| Lamp power [W] | 15 - 15 |
| Colour temperature [K] | 3000 - 3000 |
| Diameter [mm] | 121 |
| Length [mm] | 132 |
| Dimmable | Yes |
| Lamp shape | Reflector |
| Beam angle [°] | 40 - 40 |
| Colour | White |
| Type of glass/cover | Clear |
| Lamp designation | PAR38 |
| Colour rendering index CRI | 80-89 |
| Voltage type | AC |
| Filament lamp | No |
| Luminous intensity [cd] | 2066 |
| Rated luminous flux according to IEC 62612 [lm] | 77 |
| Power factor | 0.8 |
| Nominal current [mA] | 70 - 70 |
| Colour of light according to EN 12464-1 | Warm white < 3300 K |
| Housing colour | White |
| Average nominal lifetime [h] | 15000 |
| Degree of protection (IP) | IP65 |
| Colour consistency (McAdam ellipse) | SDCM6 |
| Min. number of switching cycles | 15000 |
| Weighted energy consumption in 1000 hours [kWh] | 15 |
| Remote operation possible | No |
| With movement sensor | No |
| With remote control | No |
| Photobiological safety according to EN 62471 | RG1 |
| Compatible with Apple HomeKit | No |
| Compatible with Google Assistant | No |
| Compatible with Amazon Alexa | No |
| IFTTT support available | No |
| Suitable for electronic ballast | No |
| Suitable for magnetic ballast | No |
| Dimming phase cut-off (trailing edge) | Yes |
| Dimming phase cut-on (leading edge) | Yes |
| Dimming Touch and Dim | No |
| Dimming Zigbee | No |

| | |
|--|----|
| Dimming Bluetooth | No |
| Dimming Wi-Fi | No |
| Energy efficiency class according to EU regulation 2019/2015 | F |
| With twilight switch | No |

Alternative articles



145517

LED Spot PAR38 E27 DIM 15W
(120W) 1150lm 840 40° IP65