

Product datasheet

Specifications



inductive sensor XS4 M18 - L34mm
- PPS - Sn8mm - 12..24VDC - cable
2m

XS4P18PC410TF

⚠ Discontinued on: 01 November 2020

⚠ Discontinued

Main

Range of product	Telemecanique Inductive proximity sensors XS
Series name	General purpose
Sensor type	Inductive proximity sensor
Sensor name	XS4
Sensor design	Cylindrical M18
Size	34 mm
Body type	Fixed
Detector flush mounting acceptance	Non flush mountable
Material	Plastic
Type of output signal	Discrete
Wiring technique	4-wire
[Sn] nominal sensing distance	8 mm
Discrete output function	1 NO + 1 NC
Output circuit type	DC
Discrete output type	PNP
Electrical connection	Cable
Cable length	2 m
[Us] rated supply voltage	12...24 V DC with reverse polarity protection
Switching capacity in mA	<= 200 mA with overload and short-circuit protection
IP degree of protection	IP68 double insulation conforming to IEC 60529

Complementary

Thread type	M18 x 1
Detection face	Frontal
Front material	PPS
Enclosure material	PPS
Operating zone	0...6.4 mm

Differential travel	1...15% of Sr
Cable composition	4 x 0.22 mm²
Wire insulation material	PvR
Status LED	Output state: 1 LED (yellow)
Supply voltage limits	10...36 V DC
Switching frequency	<= 2000 Hz
Maximum voltage drop	<2 V (closed)
Current consumption	0...10 mA no-load
Maximum delay first up	5 ms
Maximum delay response	0.15 ms
Maximum delay recovery	0.35 ms
Marking	CE
Threaded length	26 mm
Height	18 mm
Length	34 mm
Net weight	0.09 kg

Environment

Product certifications	UL CSA
Ambient air temperature for operation	-40...70 °C
Ambient air temperature for storage	-40...85 °C
Vibration resistance	25 gn amplitude = +/- 2 mm (f = 10...55 Hz) conforming to IEC 60068-2-6
Shock resistance	50 gn for 11 ms conforming to IEC 60068-2-27

Packing Units


Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	100.0 g
Package 1 Height	4.2 cm
Package 1 width	9.5 cm
Package 1 Length	13 cm
Unit Type of Package 2	BAG
Number of Units in Package 2	1
Package 2 Weight	0.1 kg
Package 2 Height	3 cm
Package 2 width	20 cm
Package 2 Length	15 cm

Offer Sustainability

Sustainable offer status	Green Premium product
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration


Mercury free	Yes
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information
Contractual warranty	
Warranty	18 months

Dimensions

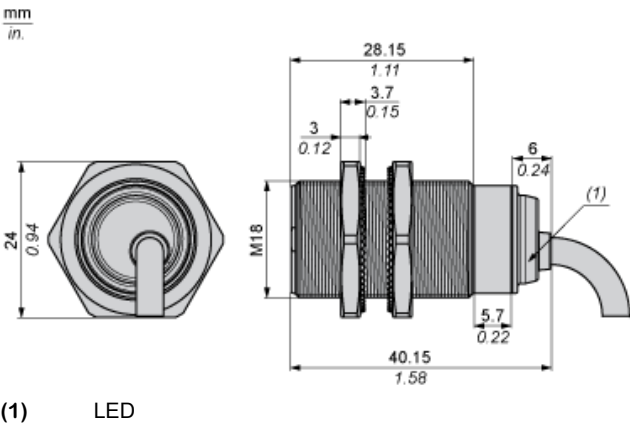


Minimum Mounting Distances

Side by side

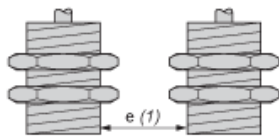


e (1) ≥ 32 mm/1.26 in.

 Face to face




e (2) ≥ 96 mm/3.78 in.

Facing a metal object

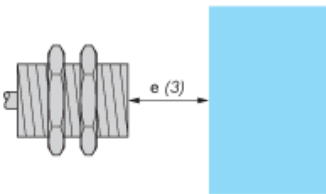


e (3) ≥ 24 mm/0.94 in.

Mounted in a metal support

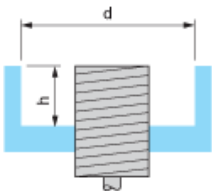

d ≥ 56 mm/2.20 in.
h ≥ 16 mm/0.63 in.


Wiring Schemes

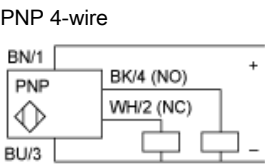

- BU : Blue
- BN : Brown
- BK : Black
- WH : White


Performance Curves

Standard Steel Target : 24x24x1 mm

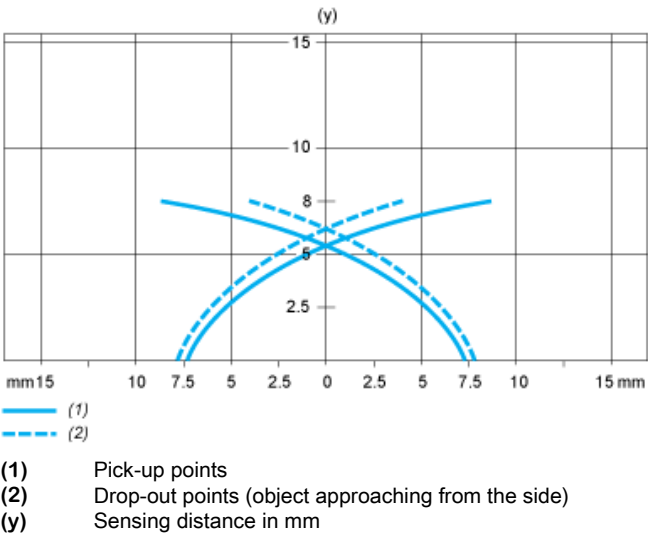

Recommended replacement(s)

XS4P18PC410TF is replaced by the following product range:



Inductive and capacitive sensors XS & XT

Inductive and capacitive proximity sensors

Products: 576