



Double hexagon Metric, A7400DM

Sockets, double hexagon in Metric sizes.

DIN 3124/ISO 2725.

3/8" 10 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.

Material: CHROMO-EXTRA.

Thin-walled, high performance sockets with Dynamic-Drive-Profile.

SB = Retail packed on a plastic info card.


These sockets are applicable to all nuts and bolts used in the aerospace industry.

DIN: 65546, 65438 - 65443

LN: 269520, 29542, 29550, 29551, 29769, 29901 - 29903, 29934, 29955, 65056, 65101 - 65106, 65416 - 65418, 29529, 29824, 29919, 65414

VLN: 29953

EN: 2907, 3013

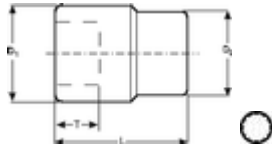

L
mm

D1
mm

D2 T
mm mm



				L mm	D1 mm	D2 mm	T mm	
A7400DM-9	1819965	5	9	25.8	12.8	17.3	7.6	19
A7400DM-10	1819972	5	10	25.8	14.3	17.3	7.6	19
A7400DM-11	1819989	5	11	25.8	15.7	17.3	7.6	19
A7400DM-12	1819996	5	12	25.8	16.5	17.3	8.5	22
A7400DM-13	1820008	5	13	25.8	18.0	17.3	8.6	22
A7400DM-14	1820015	5	14	26.2	19.6	18.0	10.7	22
A7400DM-15	1820022	5	15	27.8	20.4	19.0	10.7	26
A7400DM-16	1820039	5	16	28.3	21.1	20.0	12.2	28
A7400DM-17	1820046	5	17	28.8	22.8	20.0	12.2	30
A7400DM-18	1820053	5	18	29.5	24.3	21.0	12.7	36
A7400DM-19	1820060	5	19	30.2	25.2	22.0	12.7	39
A7400DM-20	1820077	5	20	31.0	26.3	24.0	12.7	42
A7400DM-21	1820084	5	21	31.3	28.3	25.0	12.7	49
A7400DM-22	1820091	5	22	32.6	29.1	26.0	14.5	50
SBA7400DM-9	3003812	1	9	25.8	12.8	17.3	7.6	19
SBA7400DM-10	3003829	1	10	25.8	14.3	17.3	7.6	19
SBA7400DM-11	3003836	1	11	25.8	15.7	17.3	7.6	19
SBA7400DM-12	3003843	1	12	25.8	16.5	17.3	8.6	22
SBA7400DM-13	3003850	1	13	25.8	18.0	17.3	8.6	22
SBA7400DM-14	3003867	1	14	26.2	19.6	18.0	10.7	22
SBA7400DM-15	3003874	1	15	27.8	20.4	19.0	10.7	26
SBA7400DM-16	3003881	1	16	28.3	21.1	20.0	12.2	28
SBA7400DM-17	3003898	1	17	28.8	22.8	20.0	12.2	30
SBA7400DM-18	3003904	1	18	29.5	24.3	21.0	12.7	36
SBA7400DM-19	3003911	1	19	30.2	25.2	22.0	12.7	39
SBA7400DM-20	3003928	1	20	31.0	26.3	24.0	12.7	42
SBA7400DM-21	3003935	1	21	31.3	28.3	25.0	12.7	49
SBA7400DM-22	3003942	1	22	32-6	29.1	26.0	14.6	50