

495A - Heavy-duty end nippers




Standards:

NF ISO 9242, ISO 9242, DIN ISO 9242

Description:

- Rounded, semi-rigid handles designed to turn quickly in the hand.
- 60/62 HRC high-frequency hardened cutting edges for long life.
- Cutting capacity: - To diameter 4.5 mm on soft wire (300 mm model). - Max. on hard wire 160 kg/mm².
- Finish: burnished, polished head.

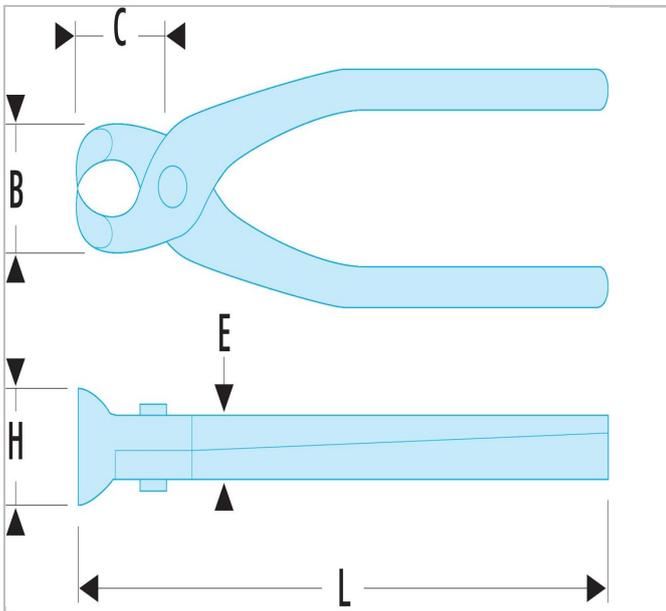

	Length L [mm]	Thickness E [mm]	Head Height C [mm]	Head Width B [mm]	Height H [mm]	Weight [g]
495A.20EL	200.0	12.0	10.0	28.0	20.0	240.0
495A.25EL	250.0	14.0	12.0	35.0	25.0	390.0
495A.28EL	280.0	14.0	12.0	35.0	25.0	450.0