


## Datasheet

**RS, 200m CW1311 Telecom Cable, 7 Strands ,  
0.14 mm<sup>2</sup> CSA**

**Stock Number – 521-3021**

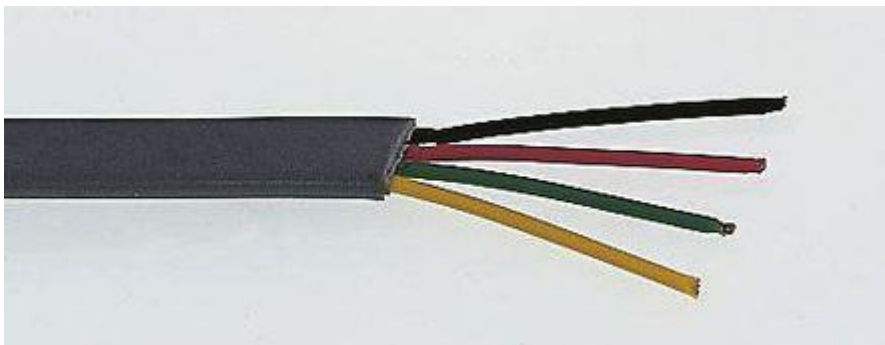

### Description:

**Rated Temperature (oC):** -20 ~ 80

**Rated Voltage (V):**30

### Construction:

**Conductor:** Tinned Copper

**Conductor Dia. (mm):** 0.16±0.008 x 7

**Insulation:** PVC

**Insulation Dia. (mm):** 0.9±0.03 x 4C

**Filler:** Chalk

**Jacket:** PVC

**Outer Dia. (±0.20mm):** 3.0 x 5.0

### Colour:

**The colour of the insulation:** White ;

Light Green ; Blue ;

Red/light green(strip)

**The jacket colour:** Black

**Marking(3times/m):**

RS 5213021 4 way line cord

**Electrical Characteristics:**

**Max.Conductor DC Resistance at 20°C (  $\Omega$ /Km ) :**

<139

**Min.Insulation DC Resistance at 20°C (  $M\Omega$ \*KM ) :**

>200

