

rotronic

Datenblatt - Fiche technique - Data sheet

17.03.1130




ROLINE PC-Halter drehbar silber,

ROLINE Support PC pivotant argent,

ROLINE PC Holder with rotation function, silver,

CPU Holder

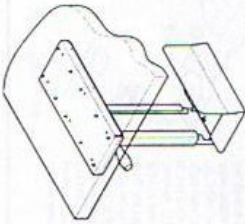

Before starting Assembly
Please spend a short time reading this manual then follow the simple step by step guide to assembly. Some panels are viewed differently from the exploded drawing below, this is for extra clarity.

Do not discard any of the packaging until you have checked all the parts and the pack of fittings. If you are missing any of the parts, contact store where you purchased. The staff will do their best to help you.

Parts Check-List

Code	Component	Qty
01	Top Bracket	1
02	Bottom Bracket	1
03	Holder	1
04	Slider	1
05	Slide Support	1
06	Handle	1

Fitting Check-List

Code	Description	Qty
07	Screw	10
08	Bolt	4
09	Screw	4
10	Nut	1
11	Spacer	1
12	Washer	1
13	Knob	1
14	Round Foam Pad	1set
15	Foam Pad	4
16	Thick Pad	2

Tools Check-List

Allen Key

Caution:

Regular cleaning with a clean dry cloth is usually sufficient, but for stubborn marks, wipe over gently with a clean damp cloth. Never use strong detergents or abrasive cleaners as these may damage the surface finish of your furniture. There are many small components used in the construction of this unit. These loose items should be kept away from young children while assembling your unit.

20021001

Assembly Guide

1 x10

Fit slide support 05 to the underside of your computer desk ensuring it is approximately 15mm back from the front edge, and far enough away from the sides of the desk to enable the CPU to fit under the desk. Using a bradawl mark the screw positions, and secure firmly with screws 07 as shown.

2 x4

Before assembling, please make sure the position you fit the top right or left side is set up in the left side, turn the "L" sign of the slider 04 onward. If you want to set it up in the right side, turn the "R" sign onward. After making sure the direction, secure slider 04 to the underside of slide support 05 with bolts 08.

Left side

3 x4 x4 x1

Secure the handle 09 to the top bracket 01 with nut 10. The handle 09 may be fitted to left or right hand side to suit left or right handed use. Secure the top bracket 01 to the slider 04 with screws 09. Fully tighten with allen key provided.

4 x1 x1 x1

Fit the holder 03, spacer 11, bottom bracket 02, washer 12 together as shown using the knob 13. Do not fix too tightly.

5 x1

Secure the fitted bottom bracket 02 to the top bracket to desired height. There are 7 stops in total; each pitch is 25mm. CPU height is available from 390mm-540mm.

6 x1set x4 x2

Remove pads cover 14, 15 & 16 and adhere to the places illustrated. Holder width extends from 134mm-234mm. Fix the knob 13 tightly after adjusting the width. And you can use the handle 06 to sliding and swivel the main structure.

CS-11

CS-11

